


TECHNICAL SPECIFICATIONS

D-Sub Hood:


Material:	UL Recognised Plastic Material
Plating:	Nickel over Copper
Operating Temperature:	-55°C to +110°C
Cable Entry:	Top Entry
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 13mm

D-Sub High Density:


Insulator:	PBT, Black, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed pins:	100 inserts min
Contacts Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	500V for 1 minute
Insulator resistance:	500MΩ min

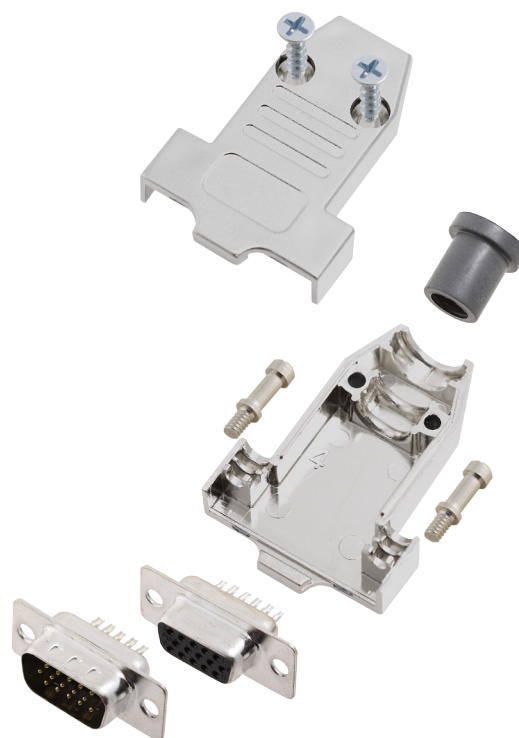

Compression Inserts - Inner Diameters:

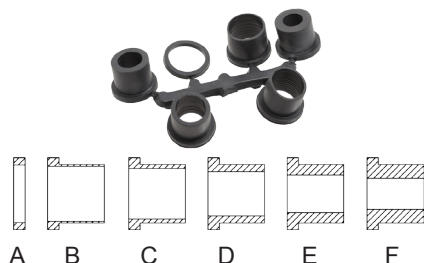

Size	A	B	C	D	E	F
9/15	8,10	8,00	7,25	6,50	5,30	-
25	11,40	10,40	9,40	7,60	5,80	-

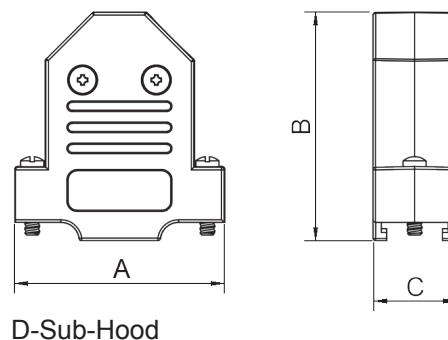

D-Sub-Hood

Size DTNT	Dim A	Dim B	Dim C
9-way	31,5	43,5	15,8
15-way	39,9	43,5	15,8
25-way	54,0	47,5	15,8

Ordering information:**D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
HD 15	6355-0071-01	DTNT09-M-HDP15-K
HD 26	6355-0071-02	DTNT15-M-HDP26-K
HD 44	6355-0071-03	DTNT25-M-HDP44-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
HD 15	6355-0071-11	DTNT09-M-HDS15-K
HD 26	6355-0071-12	DTNT15-M-HDS26-K
HD 44	6355-0071-13	DTNT25-M-HDS44-K