

TECHNICAL SPECIFICATIONS

D-Sub Hood:


Housing material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Top
Thumbscrews:	UNC 4-40
Cable O.D:	13mm Max.

Male D-Sub Solder Cup:

Insulator:	PBT, Black, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed Pins	Class 3, 100 inserts min.
Machined Contact Pins:	Class 1, 500 inserts min.
Contact Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	1000V for 1 minute
Insulator resistance:	1000MΩ min.

Features:

- D-sub hood + D-sub connector solder cup
- Available in sizes 9, 15, 25, 37 and 50-way
- Full metall cover
- Packed in Kit with male or female D-sub connector
- Class 3 or Class 1 D-sub connector as standard
- Re-openable

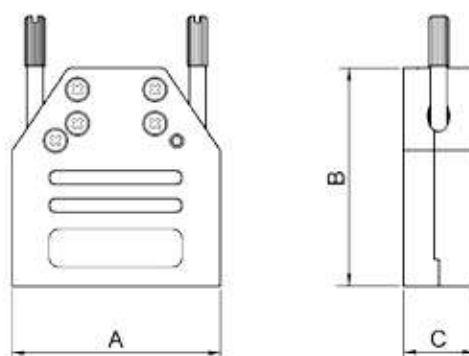

Size MHDTZI	Dim A	Dim B	Dim C
9-way	34,0	45,0	14,6
15-way	43,0	45,0	14,6
25-way	56,5	45,0	14,6
37-way	73,0	45,0	14,6
50-way	71,0	45,0	17,4

Ordering information:**Class 3 Sub-D Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
9-way	6355-0077-01	DTZI09-DBP-K
15-way	6355-0077-02	DTZI15-DBP-K
25-way	6355-0077-03	DTZI25-DBP-K
37-way	6355-0077-04	DTZI37-DBP-K
50-way	6355-0077-05	DTZI50-DBP-K

Ordering information:**Class 1 Sub-D Connector Kits (500 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
9-way	6355-0077-21	DTZI09-DMP-K
15-way	6355-0077-22	DTZI15-DMP-K
25-way	6355-0077-23	DTZI25-DMP-K
37-way	6355-0077-24	DTZI37-DMP-K
50-way	6355-0077-25	DTZI50-DMP-K



TECHNICAL SPECIFICATIONS

D-Sub Hood:


Housing material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Top
Thumbscrews:	UNC 4-40
Cable O.D.:	13mm Max.

Female D-Sub Solder Cup:

Insulator:	PBT, Black, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed Pins	Class 3, 100 inserts min.
Machined Contact Pins:	Class 1, 500 inserts min.
Contact Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	1000V for 1 minute
Insulator resistance:	1000MΩ min

Features:

- D-sub hood + D-sub connector solder cup
- Available in sizes 9, 15, 25, 37 and 50-way
- Full metall cover
- Packed in Kit with male or female D-sub connector
- Class 3 or Class 1 D-sub connector as standard
- Re-openable

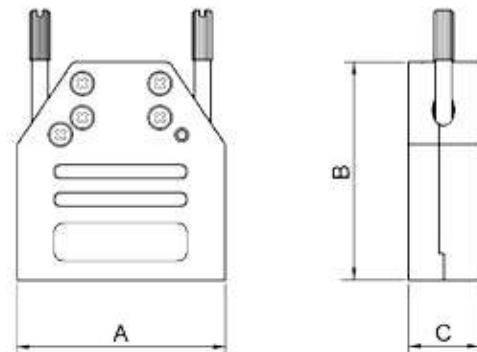

Size MHDTZI	Dim A	Dim B	Dim C
9-way	34,0	45,0	14,6
15-way	43,0	45,0	14,6
25-way	56,5	45,0	14,6
37-way	73,0	45,0	14,6
50-way	71,0	45,0	17,4

Ordering information:**Class 3 Sub-D Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
9-way	6355-0077-11	DTZI09-DBS-K
15-way	6355-0077-12	DTZI15-DBS-K
25-way	6355-0077-13	DTZI25-DBS-K
37-way	6355-0077-14	DTZI37-DBS-K
50-way	6355-0077-15	DTZI50-DBS-K

Ordering information:**Class 1 Sub-D Connector Kits (500 inserts min.)**

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
9-way	6355-0077-31	DTZI09-DMS-K
15-way	6355-0077-32	DTZI15-DMS-K
25-way	6355-0077-33	DTZI25-DMS-K
37-way	6355-0077-34	DTZI37-DMS-K
50-way	6355-0077-35	DTZI50-DMS-K



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90
Fax: +46-(0)35-15 13 99

www.encitech.com