

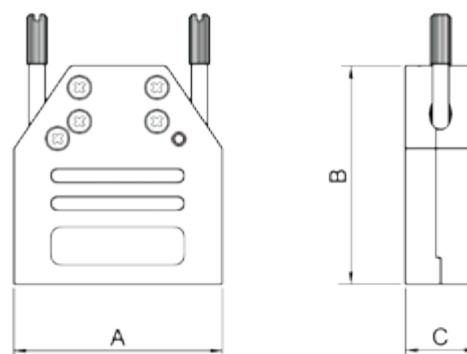
TECHNICAL SPECIFICATIONS

D-Sub Hood:

Housing material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Top
Thumbscrews:	UNC 4-40
Cable O.D:	13mm Max.

D-Sub Crimp:

Insulator:	PBT, Black, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Machined pins Class 2:	200 inserts min
Contacts Plating:	Hard Gold over Nickel
Operating Temperature:	-55°C to +125°C
Test voltage:	1000V
Insulator resistance:	<5GΩ
Crimp Area (AWG):	AWG 24-20 0.2 - 0.6mm ²

**Features:**

- D-sub hood + D-sub connector solder cup
- Available in sizes 9, 15, 25, 37 and 50-way
- Full metall cover
- Packed in Kit with male or female D-sub connector
- Class 3 or Class 1 D-sub connector as standard
- Re-openable

Size MHDZTI	Dim A	Dim B	Dim C
9-way	34,0	45,0	14,6
15-way	43,0	45,0	14,6
25-way	56,5	45,0	14,6
37-way	73,0	45,0	14,6
50-way	71,0	45,0	17,4

Ordering information:**Class 3 D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
9-way	6355-0079-01	DTZI09-DBCP-K
15-way	6355-0079-02	DTZI15-DBCP-K
25-way	6355-0079-03	DTZI25-DBCP-K
37-way	6355-0079-04	DTZI37-DBCP-K
50-way	6355-0079-05	DTZI50-DBCP-K

Ordering information:**Class 3 D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
9-way	6355-0079-11	DTZI09-DBCS-K
15-way	6355-0079-12	DTZI15-DBCS-K
25-way	6355-0079-13	DTZI25-DBCS-K
37-way	6355-0079-14	DTZI37-DBCS-K
50-way	6355-0079-15	DTZI50-DBCS-K



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90
Fax: +46-(0)35-15 13 99

www.encitech.com