

TECHNICAL SPECIFICATIONS

D-Sub Hood:


Material:	Zinc, Black Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Top Entry
Thumbscrews:	UNC 4-40 (Standard) M2,5 or M3 on request
Cable O.D:	Up to 11,5mm

D-Sub High Density:

Insulator:	PBT, Black, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed pins:	100 inserts min
Contacts Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	500V for 1 minute
Insulator resistance:	500MΩ min

Features:

- Available in sizes 9-15-25-37
- Excellent EMI Shielding
- Re-openable
- Strain relief inserts ensure a secure termination
- Black Full Metal Jackscrew as standard

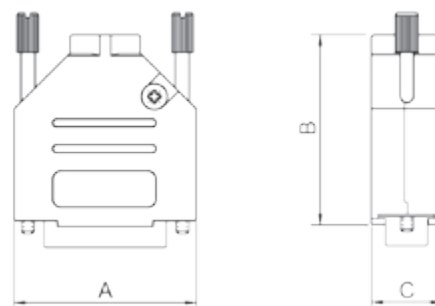

Size DTZK	Dim A	Dim B	Dim C
9-way	31,0	39,5	15,0
15-way	39,5	41,5	15,0
25-way	53,5	48,5	15,0
37-way	71,0	53,0	15,0

Ordering information:**Class 3 D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
15-way	6355-0102-01	DTZK09-BK-HDP15-K
26-way	6355-0102-02	DTZK15-BK-HDP26-K
44-way	6355-0102-03	DTZK25-BK-HDP44-K
62-way	6355-0102-04	DTZK37-BK-HDP62-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
15-way	6355-0102-11	DTZK09-BK-HDS15-K
26-way	6355-0102-12	DTZK15-BK-HDS26-K
44-way	6355-0102-13	DTZK25-BK-HDS44-K
62-way	6355-0102-14	DTZK37-BK-HDS62-K

