

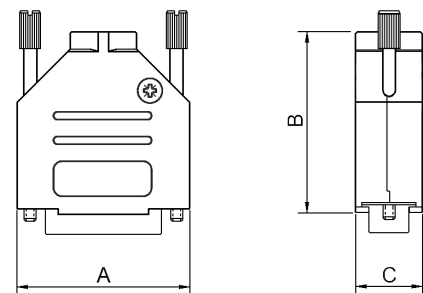
TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Top Entry
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 11,5mm (Size 9-37) Up to 17mm (Size 50)

Female D-Sub Solder Cup:

Insulator:	PBT, Black, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed Pins	Class 3, 100 inserts min.
Machined Contact Pins:	Class 1, 500 inserts min.
Contact Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	1000V for 1 minute
Insulator resistance:	1000MΩ min.

**Features:**

- Available in sizes 9-15-25-37-50
- Packed in Kit with FEMALE D-connector
- Class 3 or Class 1 connector as standard options
- Re-openable
- Full Metal Jackscrew as standard.

Size DTZK	Dim A	Dim B	Dim C
9-way	31,0	39,5	15,0
15-way	39,5	41,5	15,0
25-way	53,5	48,5	15,0
37-way	71,0	53,0	15,0
50-way	67,5	54,0	18,7

Ordering information - Black Insulator:

Size:	P/N - Kitted:	Class 3 - 100 inserts min.
9-way	6355-0002-11	DTZK09-DBS-K
15-way	6355-0002-12	DTZK15-DBS-K
25-way	6355-0002-13	DTZK25-DBS-K
37-way	6355-0002-14	DTZK37-DBS-K
50-way	6355-0002-15	DTZK50-DBS-K

Size:	P/N - Kitted:	Class 1 - 500 inserts min.
9-way	6355-0002-31	DTZK09-DMS-K
15-way	6355-0002-32	DTZK15-DMS-K
25-way	6355-0002-33	DTZK25-DMS-K
37-way	6355-0002-34	DTZK37-DMS-K
50-way	6355-0002-35	DTZK50-DMS-K

Ordering information - White Insulator:

Size:	P/N - Kitted:	Class 3 - 100 inserts min.
9-way	6355-8002-11	DTZK09-DBS-W-K
15-way	6355-8002-12	DTZK15-DBS-W-K
25-way	6355-8002-13	DTZK25-DBS-W-K
37-way	6355-8002-14	DTZK37-DBS-W-K
50-way	6355-8002-15	DTZK50-DBS-W-K

Size:	P/N - Kitted:	Class 1 - 500 inserts min.
9-way	6355-8002-31	DTZK09-DMS-W-K
15-way	6355-8002-32	DTZK15-DMS-W-K
25-way	6355-8002-33	DTZK25-DMS-W-K
37-way	6355-8002-34	DTZK37-DMS-W-K
50-way	6355-8002-35	DTZK50-DMS-W-K

