

TECHNICAL SPECIFICATIONS

D-Sub Hood:



Material:	UL 94 V-0 Plastic Material
Plating:	Nickel over Copper
Operating Temperature:	-55°C to +110°C
Cable Entry:	Side Entry
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 11,5mm

Male D-Sub Solder Cup:

Insulator:	PBT, Black, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed Pins	Class 3, 100 inserts min.
Machined Contact Pins:	Class 1, 500 inserts min.
Contact Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	1000V for 1 minute
Insulator resistance:	1000MΩ min.

Features:

- Available in sizes 9-15-25-37
- Suitable for any common Sub-D Connector
- Strain relief inserts ensure a secure termination
- Re-openable
- Recyclable

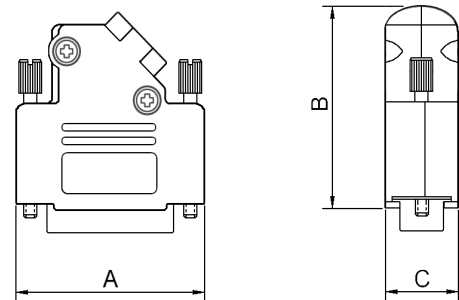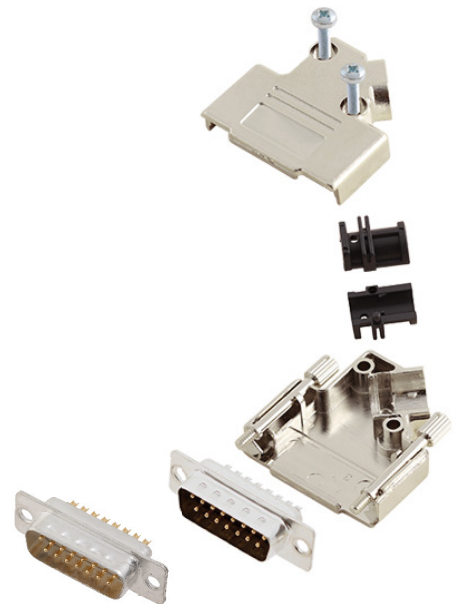

Size D45PK-M	Dim A	Dim B	Dim C
9-way	31,0	36,3	15,0
15-way	39,5	40,3	15,0
25-way	53,2	40,3	15,0
37-way	69,7	40,3	15,0

Ordering information - Black Insulator:

Size:	P/N - Kitted:	Class 3 - 100 inserts min.
9-way	6355-0009-01	D45PK-M-09-DBP-K
15-way	6355-0009-02	D45PK-M-15-DBP-K
25-way	6355-0009-03	D45PK-M-25-DBP-K
37-way	6355-0009-04	D45PK-M-37-DBP-K

Size:	P/N - Kitted:	Class 1 - 500 inserts min.
9-way	6355-0010-01	D45PK-M-09-DMP-K
15-way	6355-0010-02	D45PK-M-15-DMP-K
25-way	6355-0010-03	D45PK-M-25-DMP-K
37-way	6355-0010-04	D45PK-M-37-DMP-K

Ordering information - White Insulator:

Size:	P/N - Kitted:	Class 3 - 100 inserts min.
9-way	6355-8009-01	D45PK-M-09-DBP-W-K
15-way	6355-8009-02	D45PK-M-15-DBP-W-K
25-way	6355-8009-03	D45PK-M-25-DBP-W-K
37-way	6355-8009-04	D45PK-M-37-DBP-W-K

Size:	P/N - Kitted:	Class 1 - 500 inserts min.
9-way	6355-8010-01	D45PK-M-09-DMP-W-K
15-way	6355-8010-02	D45PK-M-15-DMP-W-K
25-way	6355-8010-03	D45PK-M-25-DMP-W-K
37-way	6355-8010-04	D45PK-M-37-DMP-W-K

