

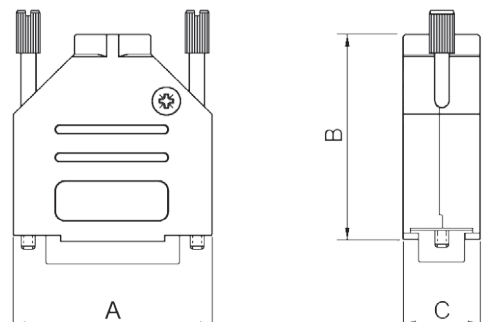
TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Top Entry
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 11,5mm (Size 9-37) Up to 17mm (Size 50)

D-Sub High Density:

Insulator:	PBT, White, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed pins:	100 inserts min
Contacts Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	500V for 1 minute
Insulator resistance:	500MΩ min

**Features:**

- Available in sizes HD15-26-44-62
- Packed in Kit with HD-connector
- Re-openable
- Full Metal Jackscrew as standard.

Size DTZK	Dim A	Dim B	Dim C
9-way	31,0	39,5	15,0
15-way	39,5	41,5	15,0
25-way	53,5	48,5	15,0
37-way	71,0	53,0	15,0

Ordering information:**Class 3 D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
HD 15	6355-8012-01	DTZK09-HDP15-W-K
HD 26	6355-8012-02	DTZK15-HDP26-W-K
HD 44	6355-8012-03	DTZK25-HDP44-W-K
HD 62	6355-8012-04	DTZK37-HDP62-W-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
HD 15	6355-8012-11	DTZK09-HDS15-W-K
HD 26	6355-8012-12	DTZK15-HDS26-W-K
HD 44	6355-8012-13	DTZK25-HDS44-W-K
HD 62	6355-8012-14	DTZK37-HDS62-W-K

