



TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	UL 94 V-0 Plastic Material
Operating Temperature:	-55°C to +110°C
Cable Entry:	Side
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D.:	Up to 11,5mm
Colour:	Black

Male Sub-D Connector:

Insulator:	PBT, Black, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed Pins	Class 3, 100 inserts min.
Machined Contact Pins:	Class 1, 500 inserts min.
Contact Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	1000V for 1 minute
Insulator resistance:	1000MΩ min.

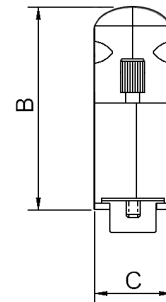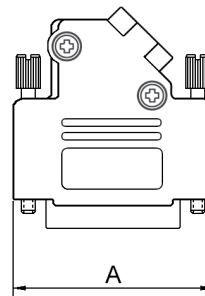

Features:

- Available in sizes 9-15-25-37
- Suitable for any common Sub-D connector
- Strain relief inserts ensure a secure termination
- Re-openable

Size D45PK-P	Dim A	Dim B	Dim C
9-way	31,0	36,3	15,0
15-way	39,5	40,3	15,0
25-way	53,2	40,3	15,0
37-way	69,7	40,3	15,0

Ordering information - Black Insulator:

Size:	P/N - Kitted:	Class 3 - 100 inserts min.
9-way	6355-0034-01	D45PK-P-09-DBP-K
15-way	6355-0034-02	D45PK-P-15-DBP-K
25-way	6355-0034-03	D45PK-P-25-DBP-K
37-way	6355-0034-04	D45PK-P-37-DBP-K

Size:	P/N - Kitted:	Class 1 - 500 inserts min.
9-way	6355-0035-01	D45PK-P-09-DMP-K
15-way	6355-0035-02	D45PK-P-15-DMP-K
25-way	6355-0035-03	D45PK-P-25-DMP-K
37-way	6355-0035-04	D45PK-P-37-DMP-K

Ordering information - White Insulator:

Size:	P/N - Kitted:	Class 3 - 100 inserts min.
9-way	6355-8034-01	D45PK-P-09-DBP-W-K
15-way	6355-8034-02	D45PK-P-15-DBP-W-K
25-way	6355-8034-03	D45PK-P-25-DBP-W-K
37-way	6355-8034-04	D45PK-P-37-DBP-W-K

Size:	P/N - Kitted:	Class 1 - 500 inserts min.
9-way	6355-8035-01	D45PK-P-09-DMP-W-K
15-way	6355-8035-02	D45PK-P-15-DMP-W-K
25-way	6355-8035-03	D45PK-P-25-DMP-W-K
37-way	6355-8035-04	D45PK-P-37-DMP-W-K

