

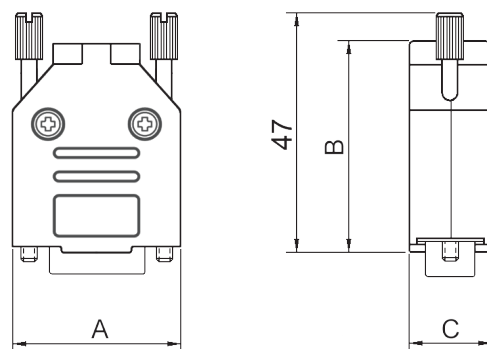
TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	UL 94 V-0 Plastic Material
Operating Temperature:	-55°C to +110°C
Cable Entry:	Top
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 11,5mm
Colour:	Black

D-Sub High Density:

Insulator:	PBT, White, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed pins:	100 inserts min
Contacts Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	500V for 1 minute
Insulator resistance:	500MΩ min

**Features:**

- Available in sizes HD15-26-44-62
- Suitable for any common Sub-D connector
- Strain relief inserts ensure a secure termination
- Re-openable

Size DTPK-P	Dim A	Dim B	Dim C
9-way	31,2	39,9	15,0
15-way	39,5	41,5	15,0
25-way	53,4	48,6	15,0
37-way	69,7	53,6	15,0

Ordering information:**D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
HD 15	6355-8053-01	DTPK-P-09-HDP15-W-K
HD 26	6355-8053-02	DTPK-P-15-HDP26-W-K
HD 44	6355-8053-03	DTPK-P-25-HDP44-W-K
HD 62	6355-8053-04	DTPK-P-37-HDP62-W-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
HD 15	6355-8053-11	DTPK-P-09-HDS15-W-K
HD 26	6355-8053-12	DTPK-P-15-HDS26-W-K
HD 44	6355-8053-13	DTPK-P-25-HDS44-W-K
HD 62	6355-8053-14	DTPK-P-37-HDS62-W-K

