

TECHNICAL SPECIFICATIONS
D-Sub Hood:


Material:	UL 94 V-0 Plastic Material
Plating:	Nickel over Copper
Operating Temperature:	-55°C to +110°C
Cable Entry:	Side Entry
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	Up to 11,5mm

D-Sub High Density:

Insulator:	PBT, White, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed pins:	100 inserts min
Contacts Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	500V for 1 minute
Insulator resistance:	500MΩ min

Features:

- Available in sizes HD15-26-44-62
- Suitable for any common D-Sub Connector
- Strain relief inserts ensure a secure termination
- Re-openable
- Recyclable

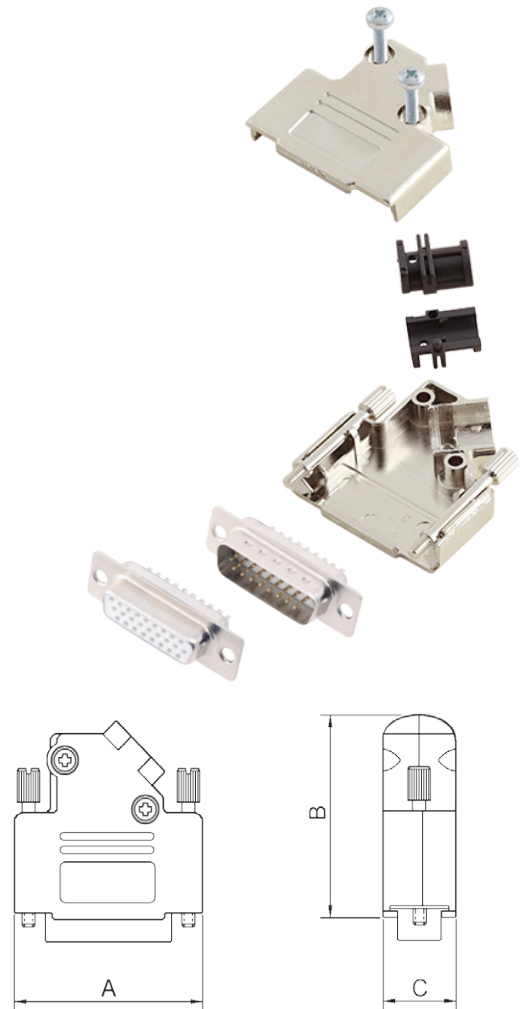

Size D45PK-M	Dim A	Dim B	Dim C
9-way	31,0	36,3	15,0
15-way	39,5	40,3	15,0
25-way	53,2	40,3	15,0
37-way	69,7	40,3	15,0

Ordering information:
Class 3 D-Sub Connector Kits (100 inserts min.)

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
15-way	6355-8057-01	D45PK-M-09-HDP15-W-K
26-way	6355-8057-02	D45PK-M-15-HDP26-W-K
44-way	6355-8057-03	D45PK-M-25-HDP44-W-K
62-way	6355-8057-04	D45PK-M-37-HDP62-W-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
15-way	6355-8057-11	D45PK-M-09-HDS15-W-K
26-way	6355-8057-12	D45PK-M-15-HDS26-W-K
44-way	6355-8057-13	D45PK-M-25-HDS44-W-K
62-way	6355-8057-14	D45PK-M-37-HDS62-W-K

