

TECHNICAL SPECIFICATIONS

D-Sub Hood:


Material:	Zinc, Nickel Plated
Operating Temperature:	-45°C to + 105°C
Cable Entry:	Top Entry
Thumbscrews:	UNC 4-40 (Standard)
Cable O.D:	9-Way: Up to 9,5mm 15-Way: Up to 12,5mm 25-Way: Up to 12,5mm 37-Way: Up to 15,5mm

D-Sub High Density:

Insulator:	PBT, White, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed pins:	100 inserts min
Contacts Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	500V for 1 minute
Insulator resistance:	500MΩ min

Features:

- Available in sizes HD15-26-44-62
- Excellent EMI Shielding
- Re-openable
- Spring-Clip mounted Jackscrews

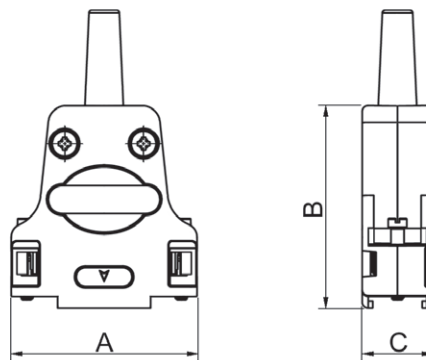

Size DTZF	Dim A	Dim B	Dim C
9-way	31,6	39,5	15,2
15-way	40,0	41,0	15,2
25-way	53,7	47,5	15,2
37-way	70,2	48,0	15,2

Ordering information:**Class 3 D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
HD 15	6355-8063-01	DTZF09-HDP15-W-K
HD 26	6355-8063-02	DTZF15-HDP26-W-K
HD 44	6355-8063-03	DTZF25-HDP44-W-K
HD 62	6355-8063-04	DTZF37-HDP62-W-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
HD 15	6355-8063-11	DTZF09-HDS15-W-K
HD 26	6355-8063-12	DTZF15-HDS26-W-K
HD 44	6355-8063-13	DTZF25-HDS44-W-K
HD 62	6355-8063-14	DTZF37-HDS62-W-K

