

TECHNICAL SPECIFICATIONS

D-Sub Hood:


Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	90° Side Entry
Jackscrews:	UNC 4-40
Cable O.D:	Up to 11,5mm
Type of grommets:	2 piece Plastic Ferrule Kit

Female D-Sub Solder Cup:

Insulator:	PBT, Black, UL94 V-0
Shell:	Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed Pins	Class 3, 100 inserts min.
Machined Contact Pins:	Class 1, 500 inserts min.
Contact Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	1000V for 1 minute
Insulator resistance:	1000MΩ min.

Features:

- Available in sizes 9-15-25-37
Other sizes on request
- Suitable for any common Sub-D connector
- Re-Openable

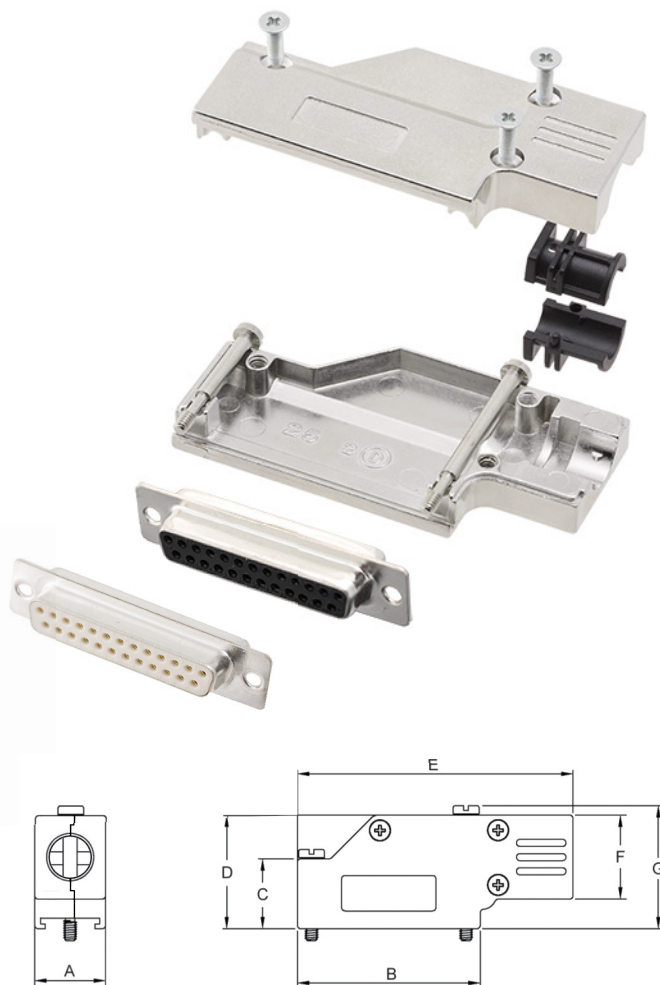

Size	A	B	C	D	E	F	G
9	15,0	31,0	15,0	24,0	51,0	18,0	26,5
15	15,3	39,2	15,0	24,0	59,0	18,0	26,5
25	16,0	54,0	23,0	34,5	73,0	24,5	37,0
37	16,0	70,5	23,0	34,5	89,5	24,5	37,0

Ordering information - Black Insulator:

Size:	P/N - Kitted:	Class 3 - 100 inserts min.
9-way	6355-0065-11	DCMR09-FK-DBS-K
15-way	6355-0065-12	DCMR15-FK-DBS-K
25-way	6355-0065-13	DCMR25-FK-DBS-K
37-way	6355-0065-14	DCMR37-FK-DBS-K

Size:	P/N - Kitted:	Class 1 - 500 inserts min.
9-way	6355-0065-31	DCMR09-FK-DMS-K
15-way	6355-0065-32	DCMR15-FK-DMS-K
25-way	6355-0065-33	DCMR25-FK-DMS-K
37-way	6355-0065-34	DCMR37-FK-DMS-K

Ordering information - White Insulator:

Size:	P/N - Kitted:	Class 3 - 100 inserts min.
9-way	6355-8065-11	DCMR09-FK-DBS-W-K
15-way	6355-8065-12	DCMR15-FK-DBS-W-K
25-way	6355-8065-13	DCMR25-FK-DBS-W-K
37-way	6355-8065-14	DCMR37-FK-DBS-W-K

Size:	P/N - Kitted:	Class 1 - 500 inserts min.
9-way	6355-8065-31	DCMR09-FK-DMS-W-K
15-way	6355-8065-32	DCMR15-FK-DMS-W-K
25-way	6355-8065-33	DCMR25-FK-DMS-W-K
37-way	6355-8065-34	DCMR37-FK-DMS-W-K

