

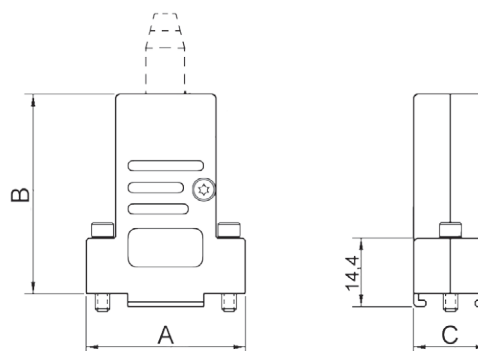
TECHNICAL SPECIFICATIONS

D-Sub Hood:

Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Top Entry Rubber Grommet RGS
Strain relief:	Clamp + Insert
Thumbscrews:	Short Jackscrews UNC 4-40 (Standard) M2,5 or M3 on request
Cable O.D.:	Up to 11.5mm

D-Sub High Density:

Insulator:	PBT, White, UL94 V-0
Shell:	Stamped Steel, Tin Plated
Contact pins:	Copper Alloy
Stamped & Formed pins:	100 inserts min
Contacts Plating:	Selective Gold over Nickel
Operating Temperature:	-55°C to +105°C
Withstanding voltage:	500V for 1 minute

**Features:**

- Full Metal D-Sub hood
- Short Jackscrews
- Universal Rubber Grommet
- 360° EMI Shielding
- Quick assembly
- Pre-mounted locking screws
- Supports all types of cables
- Suitable for any common D-Sub connector

Size DTSL	Dim A	Dim B	Dim C
9-way	32,2	42,0	15,0
15-way	40,8	42,3	15,0
25-way	54,0	42,3	15,0
37-way	70,5	48,0	15,0

Ordering information:**Class 3 D-Sub Connector Kits (100 inserts min.)**

Size:	P/N - Kitted:	Product Code - MALE Conn. Kit
HD 15	6355-8088-01	DTSL09-SJSRG-T-HDP15-W-K
HD 26	6355-8088-02	DTSL15-SJSRG-T-HDP26-W-K
HD 44	6355-8088-03	DTSL25-SJSRG-T-HDP44-W-K
HD 62	6355-8088-04	DTSL25-SJSRG-T-HDP44-W-K

Size:	P/N - Kitted:	Product Code - FEMALE Conn. Kit
HD 15	6355-8088-11	DTSL09-SJSRG-T-HDS15-W-K
HD 26	6355-8088-12	DTSL15-SJSRG-T-HDS26-W-K
HD 44	6355-8088-13	DTSL25-SJSRG-T-HDS44-W-K
HD 62	6355-8088-14	DTSL37-SJSRG-T-HDS62-W-K

