

D-Sub Metalized cover with variable cable entry



TECHNICAL SPECIFICATIONS

Material:	UL Recognised Plastic Material		
Plating:	Nickel over Copper		
Operating Temperature:	-55°C to +110°C		
Cable Entry:	Side Top Side		
Thumbscrews:	UNC 4-40 (Standard) M2,5 or M3 on request		
Cable O.D:	9-way	Up to 6,0mm	
	15-way	Up to 9,0mm	
	25-way	Up to 10,5mm	
	37-way	Up to 10,5mm	



Features:

- Available in sizes 9-15-25-37
- All sizes feature 3-Way Entry solution
- Re-openable
- Hood is supplied with 2 Blanking Plates and 2 Strain Relief clamps.
- Extra Blanking Plates and/or Strain Reliefs are available on request.
- BULK-packe on request

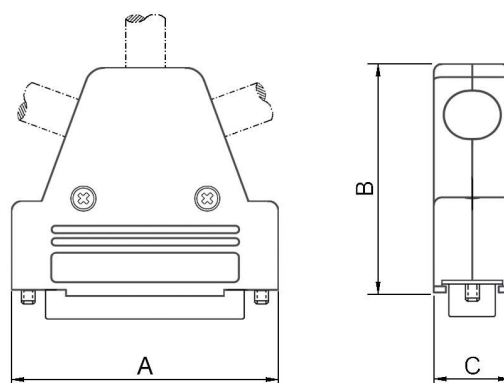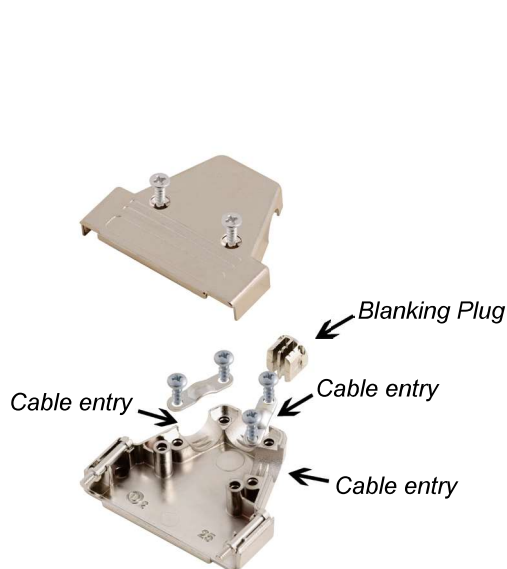

Size TRI-M	Dim A	Dim B	Dim C
9-way	31,0	45,2	15,0
15-way	40,3	45,2	15,0
25-way	53,5	45,2	15,0
37-way	70,0	45,2	15,0

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	6550-0100-01	TRI-M-09-K
15-way	6550-0100-02	TRI-M-15-K
25-way	6550-0100-03	TRI-M-25-K
37-way	6550-0100-04	TRI-M-37-K



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90
Fax: +46-(0)35-15 13 99

www.encitech.com