

D-Sub Plastic Hood, with variable cable entry



TECHNICAL SPECIFICATIONS

Material:	UL 94 V-0 Plastic Material	
Operating Temperature:	-55°C to +110°C	
Cable Entry:	Side / Top / Side	
Thumbscrews:	UNC 4-40 (Standard) M2,5 or M3 on request	
Cable O.D:	9-way	Up to 6,0mm
	15-way	Up to 9,0mm
	25-way	Up to 10,5mm
	37-way	Up to 10,5mm
Colour:	Black	



Features:

- Available in sizes 9-15-25-37
- All sizes feature 3-Way Entry solution
- Re-openable
- Supplied with 2 Blanking Plates and 2 Strain Relief clamps.
- Extra accessories are available on request.
- Also available in metalized version

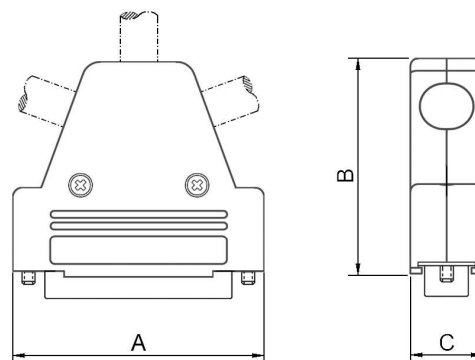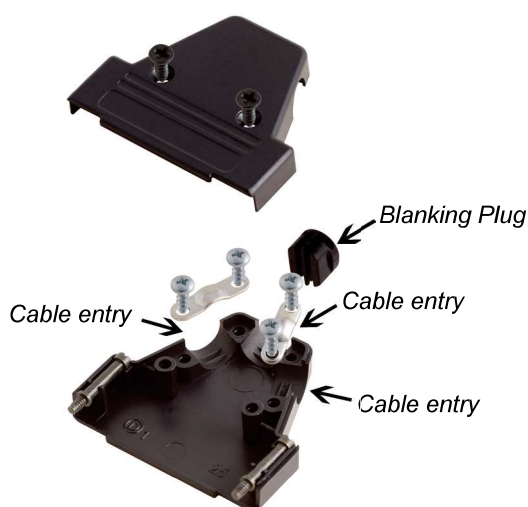

Size TRI-P	Dim A	Dim B	Dim C
9-way	31,0	45,2	15,0
15-way	40,3	45,2	15,0
25-way	53,5	45,2	15,0
37-way	70,0	45,2	15,0

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	6550-0101-01	TRI-P-09-K
15-way	6550-0101-02	TRI-P-15-K
25-way	6550-0101-03	TRI-P-25-K
37-way	6550-0101-04	TRI-P-37-K

