

D-Sub Full Metal, Side cable entry with Plastic Grommet Set

TECHNICAL SPECIFICATIONS

Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Side Entry
Thumbscrews:	UNC 4-40 (Standard) M2,5 or M3 on request
Cable O.D:	Up to 11,5mm (Size 9-37) Up to 17mm (Size 50)



Features:

- Available in sizes 9-15-25-37-50
- Size 50 equipped with extra cable clamp
- Excellent EMI Shielding
- Re-openable
- Strain relief inserts ensure a secure termination
- Full Metal Jackscrew as standard.
- Also available with Metalized (RAHI) grommets




Size 50

Size 9-15-25-37

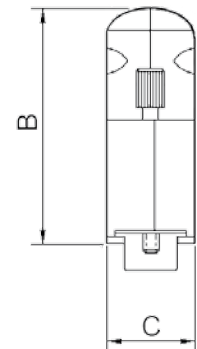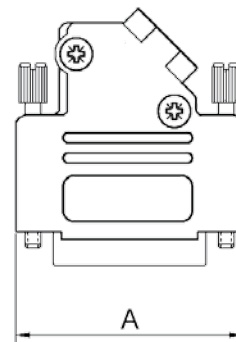


Grommet Sizes D45ZK:

 

Size 9-15-25-37



Size 50 only

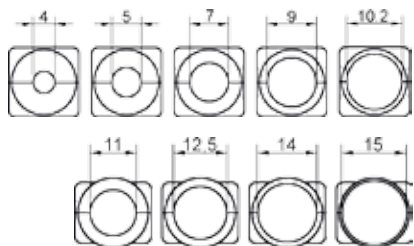

Size DTZK	Dim A	Dim B	Dim C
9-way	31,0	39,5	15,0
15-way	39,5	41,5	15,0
25-way	53,5	48,5	15,0
37-way	71,0	53,0	15,0
50-way	67,5	54,0	18,7

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	6560-0106-11	D45ZK09-K
15-way	6560-0106-12	D45ZK15-K
25-way	6560-0106-13	D45ZK25-K
37-way	6560-0106-14	D45ZK37-K
50-way	6560-0106-15	D45ZK50-K

Size:	P/N - BULK:	Product Code:
9-way	6561-0106-11	D45ZK09
15-way	6561-0106-12	D45ZK15
25-way	6561-0106-13	D45ZK25
37-way	6561-0106-14	D45ZK37
50-way	6561-0106-15	D45ZK50