

## TECHNICAL SPECIFICATIONS



|                               |                                              |              |
|-------------------------------|----------------------------------------------|--------------|
| <b>Material:</b>              | UL 94 V-0 Plastic Material                   |              |
| <b>Plating:</b>               | Nickel over Copper                           |              |
| <b>Operating Temperature:</b> | -55°C to +110°C                              |              |
| <b>Cable Entry:</b>           | Top Entry                                    |              |
| <b>Thumbscrews:</b>           | UNC 4-40 (Standard)<br>M2,5 or M3 on request |              |
| <b>Cable O.D:</b>             | 9-way                                        | Up to 11,7mm |
|                               | 15-way                                       | Up to 11,7mm |
|                               | 25-way                                       | Up to 11,7mm |
|                               | 37-way                                       | Up to 11,7mm |

## Features:

- Available in sizes 9-15-25-37
- Suitable for any common Sub-D Connector
- Strain relief inserts ensure a secure termination
- Re-openable
- Company logo available upon request
- Recyclable
- Metalized Grommet Set on request



## Grommet Sizes:

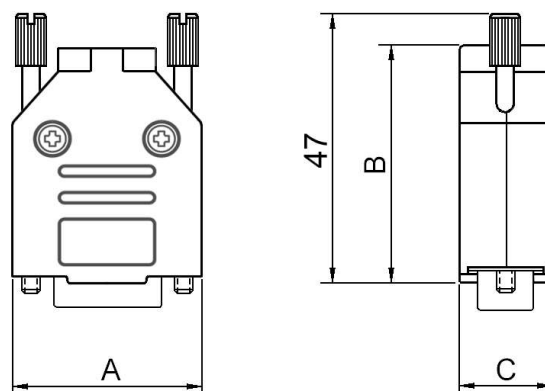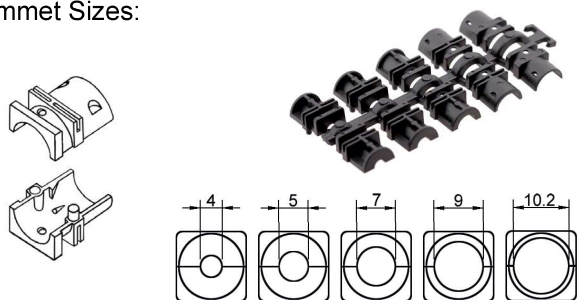

| Size DTPK-M | Dim A | Dim B | Dim C |
|-------------|-------|-------|-------|
| 9-way       | 31,2  | 39,9  | 15,0  |
| 15-way      | 39,5  | 41,5  | 15,0  |
| 25-way      | 53,4  | 48,6  | 15,0  |
| 37-way      | 69,7  | 53,6  | 15,0  |

## Ordering information:

| Size:  | P/N - Kitted: | Product Code: |
|--------|---------------|---------------|
| 9-way  | 6560-0145-01  | DTPK-M-09-K   |
| 15-way | 6560-0145-02  | DTPK-M-15-K   |
| 25-way | 6560-0145-03  | DTPK-M-25-K   |
| 37-way | 6560-0145-04  | DTPK-M-37-K   |

| Size:  | P/N - BULK:  | Product Code: |
|--------|--------------|---------------|
| 9-way  | 6561-0145-01 | DTPK-M-09     |
| 15-way | 6561-0145-02 | DTPK-M-15     |
| 25-way | 6561-0145-03 | DTPK-M-25     |
| 37-way | 6561-0145-04 | DTPK-M-37     |



**Encitech AB**  
Rörkullsvägen 4  
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90  
Fax: +46-(0)35-15 13 99

[www.encitech.com](http://www.encitech.com)