

TECHNICAL SPECIFICATIONS

Material: UL 94 V-0 Plastic Material

Plating: Nickel over Copper

Operating Temperature: -55°C to +110°C

Cable Entry: Side Entry



Thumbscrews: UNC 4-40 (Standard)
M2,5 or M3 on request

Cable O.D:


9-way	Up to 11,7mm
15-way	Up to 11,7mm
25-way	Up to 11,7mm
37-way	Up to 11,7mm

Features:

- Available in sizes 9-15-25-37
- Suitable for any common Sub-D Connector
- Strain relief inserts ensure a secure termination
- Re-openable
- Company logo available upon request
- Recyclable
- Metalized Grommet Set on request

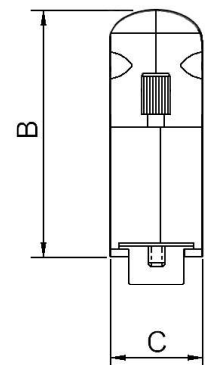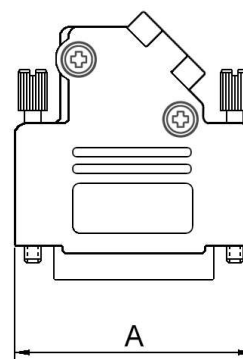

Grommet Sizes:

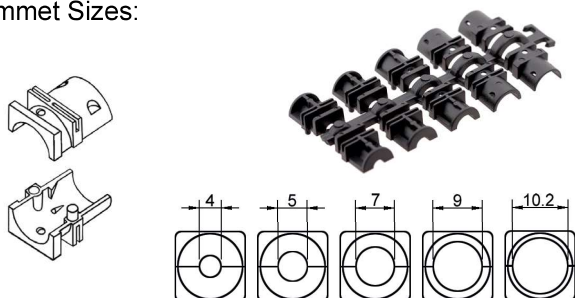

Size D45PK-M	Dim A	Dim B	Dim C
9-way	31,0	36,3	15,0
15-way	39,5	40,3	15,0
25-way	53,2	40,3	15,0
37-way	69,7	40,3	15,0

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	6560-0146-11	D45PK-M-09-K
15-way	6560-0146-12	D45PK-M-15-K
25-way	6560-0146-13	D45PK-M-25-K
37-way	6560-0146-14	D45PK-M-37-K

Size:	P/N - BULK:	Product Code:
9-way	6561-0146-11	D45PK-M-09
15-way	6561-0146-12	D45PK-M-15
25-way	6561-0146-13	D45PK-M-25
37-way	6561-0146-14	D45PK-M-37



Encitech AB
Rörkullsvägen 4
SE-302 41 HALMSTAD, Sweden

Tel.: +46-(0)35-15 13 90
Fax: +46-(0)35-15 13 99

www.encitech.com