

D-Sub Full Metal, Side + Side cable entry

TECHNICAL SPECIFICATIONS


Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Side + Side Entry
Thumbscrews:	UNC 4-40 (Standard) M2,5 or M3 on request
Cable O.D:	Up to 11,5mm

Features:

- Available in size 9
- Other sizes on request
- Excellent EMI Shielding
- Re-openable
- A variety of accessories such as Metalized grommet, Rubber grommet and Blanking plates available.


Accessories:

Universal Rubber Grommet:

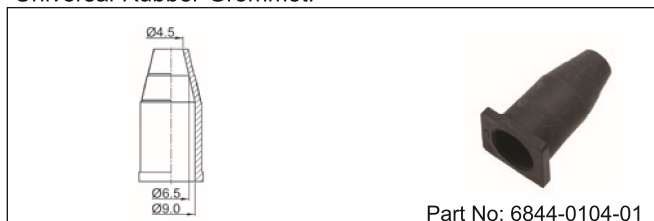


Part No: 6844-0104-01

Metalized Plastic Grommet Kit:

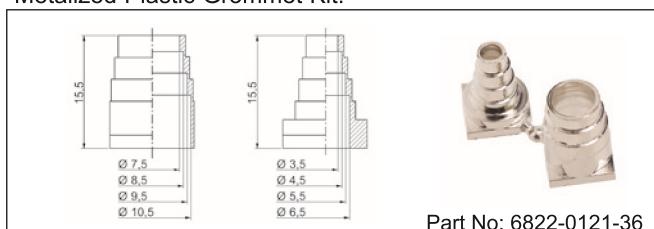

Part No: 6822-0121-36

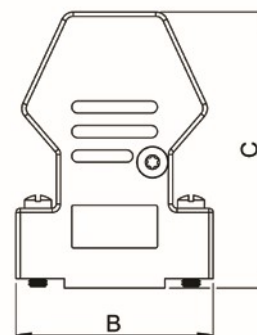

Size DYZK	Dim A	Dim B	Dim C
9-way	15	32,2	45

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	6560-0202-01	DYZK09-K

Size:	P/N - BULK:	Product Code:
9-way	6561-0202-01	DYZK09

