

D-Sub Full Metal Cover, Top Entry, Double Clamp Strain Relief


TECHNICAL SPECIFICATIONS

Material:	Zinc, Nickel Plated
Operating Temperature:	-40°C to +120°C
Cable Entry:	Straight
Jackscrews:	UNC 4-40 M2.5 or M3 on request
Cable O.D:	9-way: Up to 8,0mm 15-way: Up to 11,6mm 25-way: Up to 11,6mm 37-way: Up to 11,6mm 50-way: Up to 14,0mm



Features:

- Available in sizes 9-15-25-37-50
- Excellent EMI Shielding
- Re-openable
- Double strain relief for strong and secure cable clamping
- Short Jackscrews on request

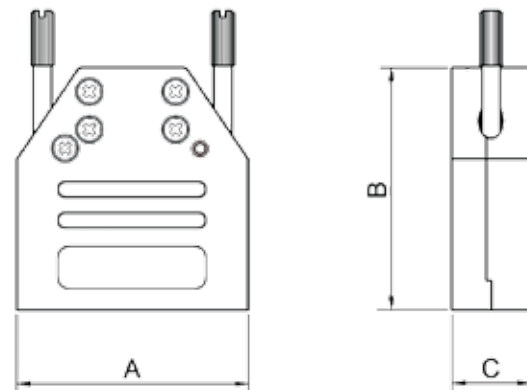

Size MHDZTI	Dim A	Dim B	Dim C
9-way	34,0	45,0	14,6
15-way	43,0	45,0	14,6
25-way	56,5	45,0	14,6
37-way	73,0	45,0	14,6
50-way	71,0	45,0	17,4

Ordering information:

Size:	P/N - Kitted:	Product Code:
9-way	6560-0305-01	DTZI09-K
15-way	6560-0305-02	DTZI15-K
25-way	6560-0305-03	DTZI25-K
37-way	6560-0305-04	DTZI37-K
50-way	6560-0305-05	DTZI50-K

Size:	P/N - Kitted:	Product Code:
9-way	6561-0305-01	DTZI09
15-way	6561-0305-02	DTZI15
25-way	6561-0305-03	DTZI25
37-way	6561-0305-04	DTZI37
50-way	6561-0305-05	DTZI50