



## D-Sub Full Metal Cover, 90° Side Entry, Metalized Grommet Set

## TECHNICAL SPECIFICATIONS



|                        |                             |
|------------------------|-----------------------------|
| Material:              | Zinc, Nickel Plated         |
| Operating Temperature: | -40°C to +120°C             |
| Cable Entry:           | 90° Side Entry              |
| Jackscrews:            | UNC 4-40, M3 on request     |
| Cable O.D:             | Up to 11,7mm                |
| Type of grommets:      | 2 piece Plastic Ferrule Kit |

## Features:

- Available in sizes 9-15-25-37-way
- Suitable for any common Sub-D connector
- Re-Openable
- Also available with Black Grommet Set (DCMR-FK)

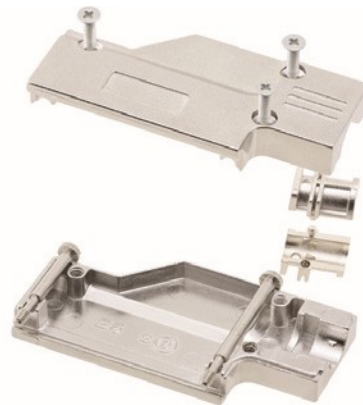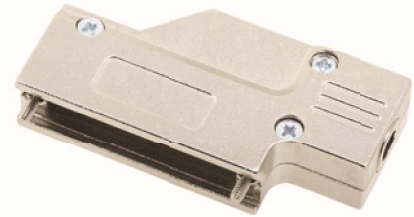

## Grommet Sizes:

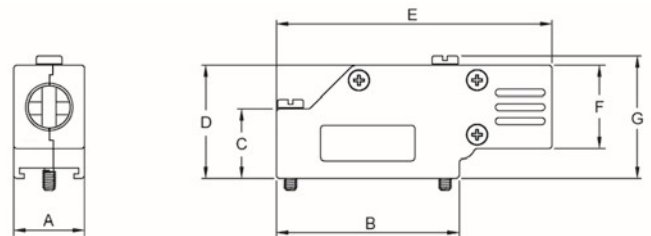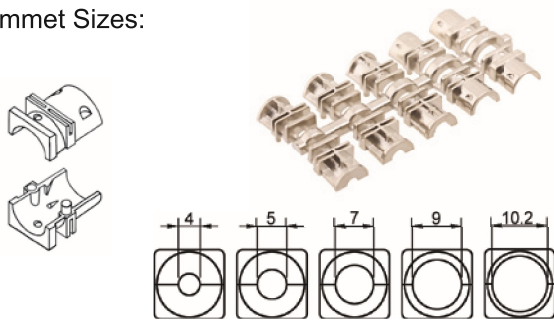

| Size | A    | B    | C    | D    | E    | F    | G    |
|------|------|------|------|------|------|------|------|
| 9    | 15,0 | 31,0 | 15,0 | 24,0 | 51,0 | 18,0 | 26,5 |
| 15   | 15,3 | 39,2 | 15,0 | 24,0 | 59,0 | 18,0 | 26,5 |
| 25   | 16,0 | 54,0 | 23,0 | 34,5 | 73,0 | 24,5 | 37,0 |
| 37   | 16,0 | 70,5 | 23,0 | 34,5 | 89,5 | 24,5 | 37,0 |

## Ordering information:

| Size:  | P/N - Kitted: | Product Code: |
|--------|---------------|---------------|
| 9-way  | 6560-0701-01  | DCMR09-HI-K   |
| 15-way | 6560-0701-02  | DCMR15-HI-K   |
| 25-way | 6560-0701-03  | DCMR25-HI-K   |
| 37-way | 6560-0701-04  | DCMR37-HI-K   |

| Size:  | P/N - BULK:  | Product Code: |
|--------|--------------|---------------|
| 9-way  | 6561-0701-01 | DCMR09-HI     |
| 15-way | 6561-0701-02 | DCMR15-HI     |
| 25-way | 6561-0701-03 | DCMR25-HI     |
| 37-way | 6561-0701-04 | DCMR37-HI     |

