


5 across flats
INTERNAL THREAD UNC 4.40

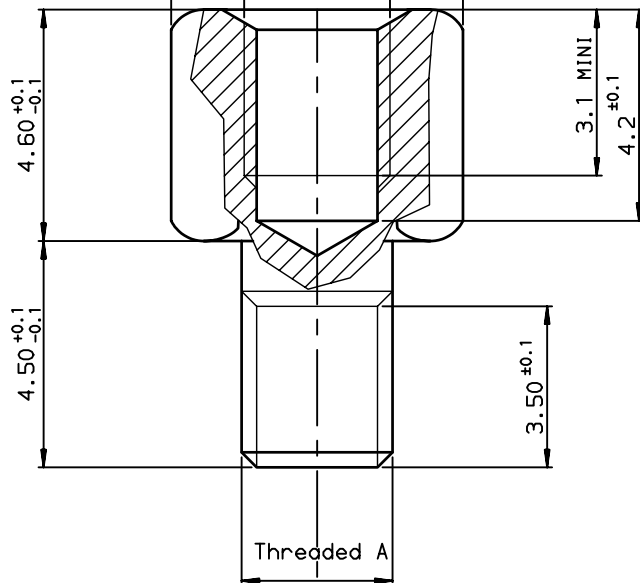

TECHNICAL CHARACTERISTICS :

Female screw locks: stell, tin plated .

Compensating washer: steel , tin plated .

Packaging : per 100 pieces .

Corrosion resistance : 24 hours exposure to salt spray .

PART NUMBER	THREADED A
863001019TLF	UNC 4.40
863001018TLF	M3

NOTE:RoHS INFORMATIONS

- The "LF" products meet European union Directives and other country regulations as described in GS-22-008.
- Plating Sn (pure bright) over copper
- Packaging spec: see GS-14-920

European Views

www.fciconnect.com			surface ISO 1302		tolerance std ISO 406 ISO 1101		projection 		mm 	
			TOLERANCES UNLESS OTHERWISE SPECIFIED							
Dr	JARRY	2000/09/18	ANGULAR	LINEAR	0.X	±0.1	size A3	Scale 10		
Eng	PESSON	2000/09/18			0.XX	±0.1				
Chr	LEGARE	2000/09/18			0.XXX	±0.1				
Appr	LEGARE	2000/09/18	Product family				D-SUB	Spec ref -		
			title FEMALE SCREW LOCKS				C01-8655-1548		Rev	
			D SUB ACCESSORIES						E	
catalog no			-				CUSTOMER		sheet 1 of 1	

rev	ecn no	dr	date
B	-	JOU	2003/01/17
C	LS05-0026	MPE	2005/07/08
D	LS06-0097	LGO	2006/07/28
E	LS09-0006	PCR	2009/01/08
-	-	-	-
-	-	-	-
-	-	-	-