

1



2

3


4

NOTES

Pieces assembly
Packaging : per 100 pieces
Material : steel
Plating : tin plated
Thread : UNC 4.40

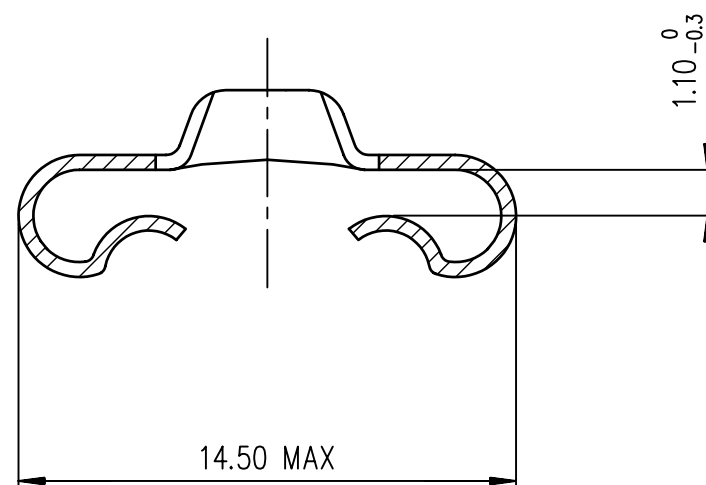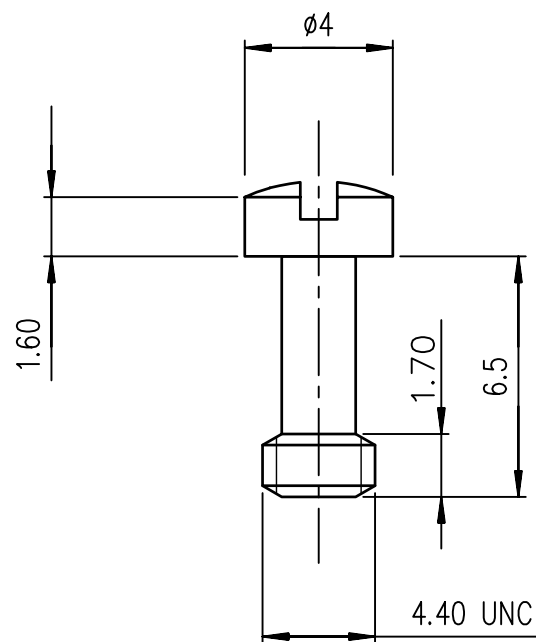

ASSEMBLY VIEW

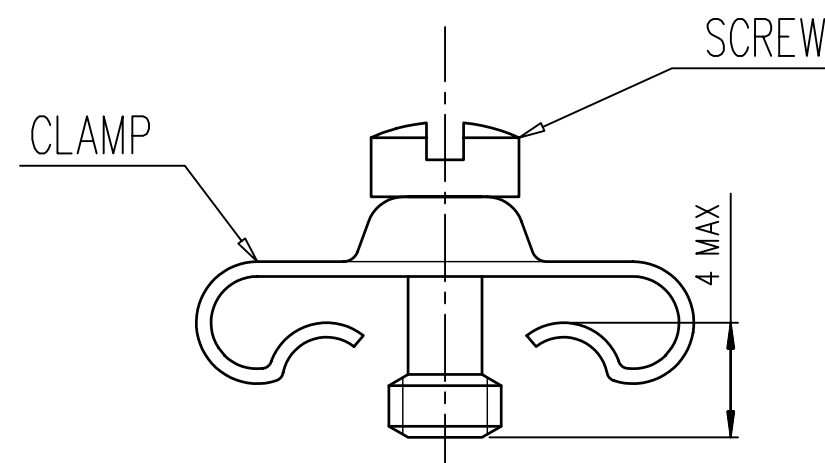

Part
number

863005ATLF

European Views

NOTE: RoHS INFORMATIONS

- The "LF" products meet European union Directives and other country regulations as described in GS-22-008.
- Plating Sn (pure bright) over copper
- Packaging spec: see GS-14-920

rev	ecn no	dr	date
A	-	JOU	2000/03/09
B	LS05-0026	MPE	2005/07/08
C	LS06-0097	LGO	2006/07/28
D	LS09-0006	PCR	2009/01/08
E	I11-0022	AMR	2011/01/25
F	ELX-H-011663	PK	2012/05/09
G	ELX-H-011686	PK	2012/05/21

www.fciconnect.com			surface ISO 1302		tolerance std ISO 406 ISO 1101		projection 		mm 		
			TOLERANCES UNLESS OTHERWISE SPECIFIED								
Dr	JOUBERT	2000/03/09	ANGULAR	LINEAR	0.X	±0.1	size A3	Scale 5			
Eng	PESSON	2000/03/09			0.XX	±0.1					
Chr	ABHILASH	2011/01/25			0.XX* ±2*	0.XXX					±0.1
Appr	SUDHIR	2011/01/25	Product family				D-SUB	Spec ref -			
			title MALE SCREWLOCK FOR HOUSINGS				dwg no C01-8655-1535			Rev. G	
			catalog no				-		CUSTOMER		sheet 1 of 1

1

2

3

4

D