

1

2

3




4

A

B

C

D

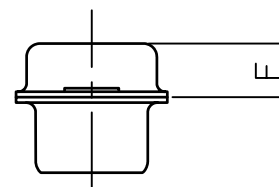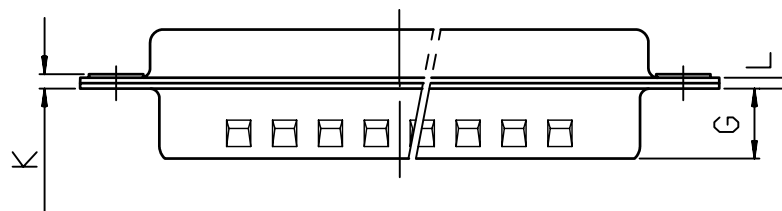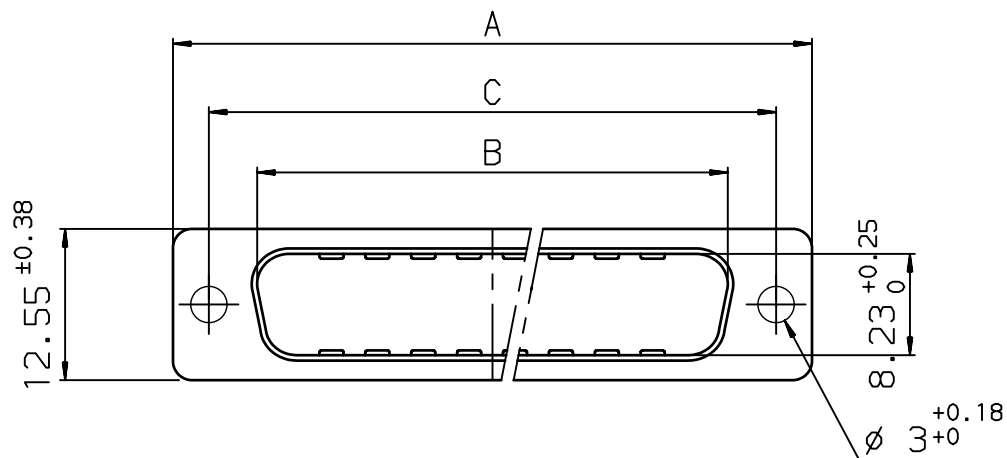

Shell size	Number of contacts	A ^{+0.76} ₀	B ^{+0.25} ₀	C ^{±0.12}	F ^{+0.13} _{-0.03}	G	K ^{max}	L ^{+0.22} ₀	Part number
E	09	30.43	16.79	24.99	4.36	5.90 ^{+0.15} ₀	1.50	0.80	86553113TLF
A	15	38.76	25.12	33.32	4.36	5.90 ^{+0.15} ₀	1.50	0.80	86553114TLF
B	25	52.65	38.84	47.04	4.36	5.70 ^{+0.25} ₀	1.50	0.80	86553115TLF
C	37	68.94	55.30	63.50	4.36	5.70 ^{+0.25} ₀	1.50	1.00	86553116TLF

NOTE: RoHS INFORMATIONS

- The "LF" product meets European union Directives and other country regulations as described in 6S-22-008.
- The product is not intended to be exposed to a manufacturing solder process.
- Plating: Sn pure bright over Copper.
- Packaging spec: see 6S-14-920.

European Views

www.fciconnect.com			surface ISO 1302	tolerance std ISO 406 ISO 1101	projection size	mm
			TOLERANCES UNLESS OTHERWISE SPECIFIED			
Dr	GOISNARD	28/06/17	ANGULAR LINEAR	0.X	±0.1	A3 Scale 3
Eng	PESSON	2006/01/12		0.XX	±0.1	
Chr	LEGARE	2006/01/12		0.XXX	±0.1	
Appr	LEGARE	2006/01/12	Product family		D-SUB	Spec ref -
			title			Rev.
			METAL CAPS			D
			D SUB ACCESSORIES			
			catalog no			
			C01-8655-1656			
			CUSTOMER			sheet 1 of 1

rev	ecn no	dr	date
A	LS05-0123	LGO	2006/01/12
B	LS06-0095	LGO	2006/06/24
C	LS07-0135	MPE	2007/05/11
D	LS09/0006	PCR	2009/01/08
-	-	-	-
-	-	-	-
-	-	-	-



1

2

3

4

A

B

C

D

4

