


## Han 4HC-Halterung

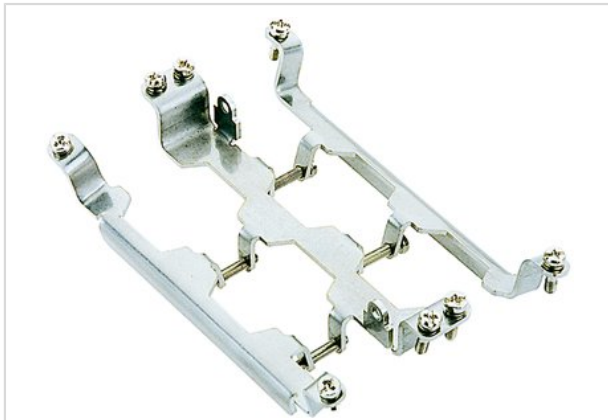

Part number	09 11 000 9954
Specification	Han 4HC-Halterung
HARTING eCatalogue	<a href="https://b2b.harting.com/09110009954">https://b2b.harting.com/09110009954</a>

### Identification

Category	Accessories
Series of hoods/housings	Han® M
Type of accessory	Frame
Description of the accessory	for male inserts for female inserts 4x HC 350 contacts + 2x Han® Q 5/0 in a hood

### Version

Size	48 B
------	------

### Technical characteristics

Tightening torque	0.5 Nm Fixing screws M3 0.25 Nm Fixing screws Han® Q 5/0 1.5 Nm Cross-tying screws
-------------------	--

### Material properties

Material (accessories)	Metal
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

### Commercial data

Packaging size	1
Net weight	77.1 g
Country of origin	Germany
Customs tariff number	85389099