


RJ45 Plug

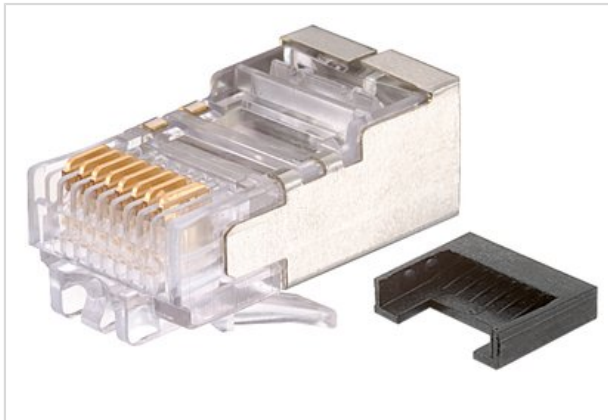

Part number	09 12 000 9958
Specification	RJ45 Plug
HARTING eCatalogue	https://b2b.harting.com/09120009958

Identification

Category	Inserts
Series	RJ45
Element	Data connectors
Specification	for Han [®] RJ45 module

Version

Gender	Male
Number of contacts	8

Technical characteristics

Limiting temperature	-40 ... +70 °C
Mating cycles	≥500
Transmission characteristics	Cat. 5 Class D up to 100 MHz
Data rate	10 Mbit/s 100 Mbit/s

Material properties

Material (insert)	Polycarbonate
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

Specifications and approvals

Specifications	EN 60664-1 IEC 61984
----------------	-------------------------



Pushing Performance

Specifications and approvals

Approvals DNV GL

Commercial data

Packaging size	10
Net weight	2.42 g
Country of origin	Germany
Customs tariff number	85366990