


Han SC module, female with 4 ferrules

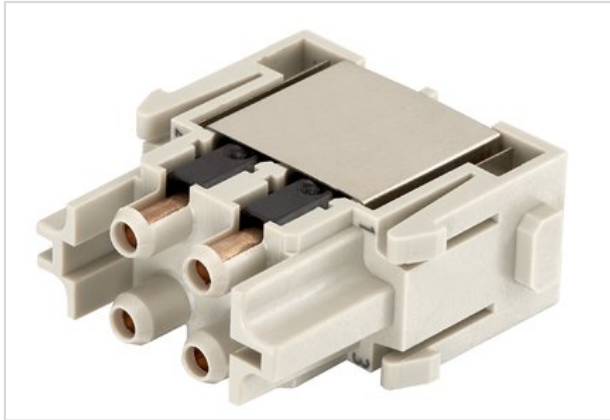

Part number	09 14 004 4711
Specification	Han SC module, female with 4 ferrules
HARTING eCatalogue	https://b2b.harting.com/09140044711

Identification

Category	Modules
Series	Han-Modular®
Type of module	Han® SC module
Description of the module with ceramic ferrule 62.5/125 µm	

Version

Gender	Female
Number of contacts	4
Details	Please order contacts separately.

Technical characteristics

Limiting temperature	-40 ... +85 °C
Mating cycles	≥500

Material properties

Material (insert)	Polycarbonate
Colour (insert)	RAL 7032 (pebble grey)
Material flammability class acc. to UL 94	V-0
RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	No
REACH ANNEX XIV substances	No
REACH SVHC substances	No

Specifications and approvals

Approvals	DNV GL
UL / CSA	UL 1977 ECBT2.E235076



Pushing Performance

Commercial data

Packaging size	2
Net weight	7.32 g
Country of origin	Germany
Customs tariff number	85389099