

Klikseal

Material: TPE and Polyamide 66

Integrated tension relief,
wide sealing range.



Suitable for holes in materials
of 1,5-5mm thickness.
Quick and simple assembly
without the use of tools.


Mode of protection: IP67

Temperature range: -20°C....+125°C

Test standard:

Semko report:

Halogen-Free

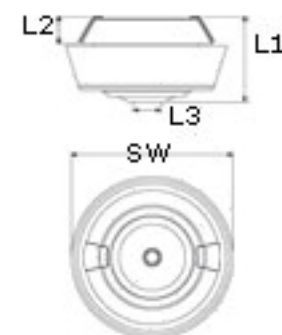

E-number Art.no	Size	For cable Ø mm	Tension relief Ø mm	A mm	B mm	L1 mm	L2 mm	L3 mm	SW* mm	Color RAL	Weight /100pcs	pcs /pack
										RAL 7035 Grey		
14 758 03	M20	4-10	5-9	20,5	1,5-5	14-18	5,3	5,0	29,7-34,5	7035	0,50	50
14 758 04	M25	4-14	6-13	25,5	1,5-5	14-18	5,3	5,0	34,7-40,0	7035	0,65	50
14 758 05	M32	11-20	12-19	32,5	1,5-5	14-18	5,3	10,0	41,7-47,5	7035	0,90	25
										RAL 9005 Black		
14 758 13	M20	4-10	5-9	20,5	1,5-5	14-18	5,3	5,0	29,7-34,5	9005	0,50	50
14 758 14	M25	4-14	6-13	25,5	1,5-5	14-18	5,3	5,0	34,7-40,0	9005	0,65	50
14 758 15	M32	11-20	12-19	32,5	1,5-5	14-18	5,3	10,0	41,7-47,5	9005	0,90	25
										RAL 9010 White		
14 758 23	M20	4-10	5-9	20,5	1,5-5	14-18	5,3	5,0	29,7-34,5	9010	0,50	50
14 758 24	M25	4-14	6-13	25,5	1,5-5	14-18	5,3	5,0	34,7-40,0	9010	0,65	50
14 758 25	M32	11-20	12-19	32,5	1,5-5	14-18	5,3	10,0	41,7-47,5	9010	0,90	25
										RAL XYZ Customer specific		
KS XYZ	M20	4-10	5-9	20,5	1,5-5	14-18	5,3	5,0	29,7-34,5	XYZ	0,50	50
KS XYZ	M25	4-14	6-13	25,5	1,5-5	14-18	5,3	5,0	34,7-40,0	XYZ	0,65	50
KS XYZ	M32	11-20	12-19	32,5	1,5-5	14-18	5,3	10,0	41,7-47,5	XYZ	0,90	25