



Data Sheet - TRU Components Cold Resistance Cable Tie

Last updated: 22 May 2024


Technical Data

Product type	: Cable tie
Material	: Nylon
Flammability	: UL 94 HB flame rated Nylon 66
Installation temperature	: -20 °C
Operating Temperature	: -40 ~ +85 °C
Content per bundle	: 100 pcs

Product Picture



Line Drawing (3133331)

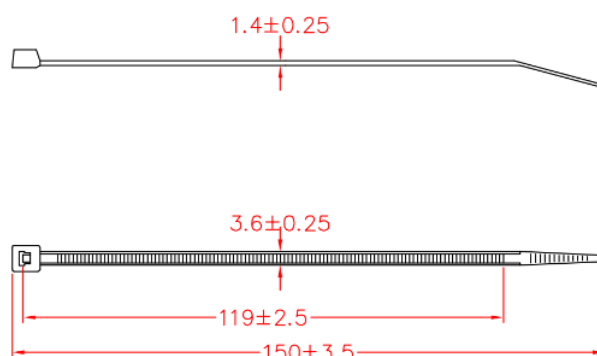

Technical Table

Article number	Length (in mm)	Width (in mm)	Minimum holding force	Color
3133331	150	3.6	18 kg	black
3130924	250	4.8	22 kg	black
3130925	300	4.8	22 kg	black
3130926	380	7.6	55 kg	black