


Item no.: 3133340, 3133341, 3133342

Data Sheet

Polypropylene Cable Ties, 100 pcs



Drawing:

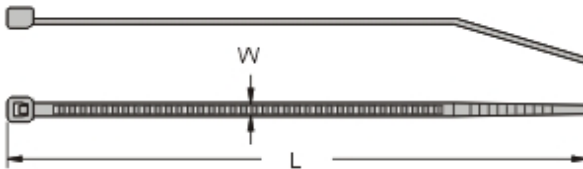

Technical data

Flammability rating: UL94 V-2

Plenum rated: AH-2

Operating temperature: -40 °C ~ 85 °C

| BN | Length (in mm) | Width (in mm) | Thickness of cable tie | Max. Bundle diameter (in mm) | Tensile strength (LBS) | Newton (N) | Color |
|---------|-------------------|------------------|---------------------------|---------------------------------------|------------------------------|---------------|-------|
| 3133340 | 200 | 4.6 | 1.5 | 52 | 22 | 100 | Black |
| 3133341 | 300 | 7.6 | 1.6 | 80 | 51 | 230 | Black |
| 3133342 | 550 | 8.0 | 2.0 | 160 | 51 | 230 | Black |