


Cable Ties (Pack 100) - Miniature Range

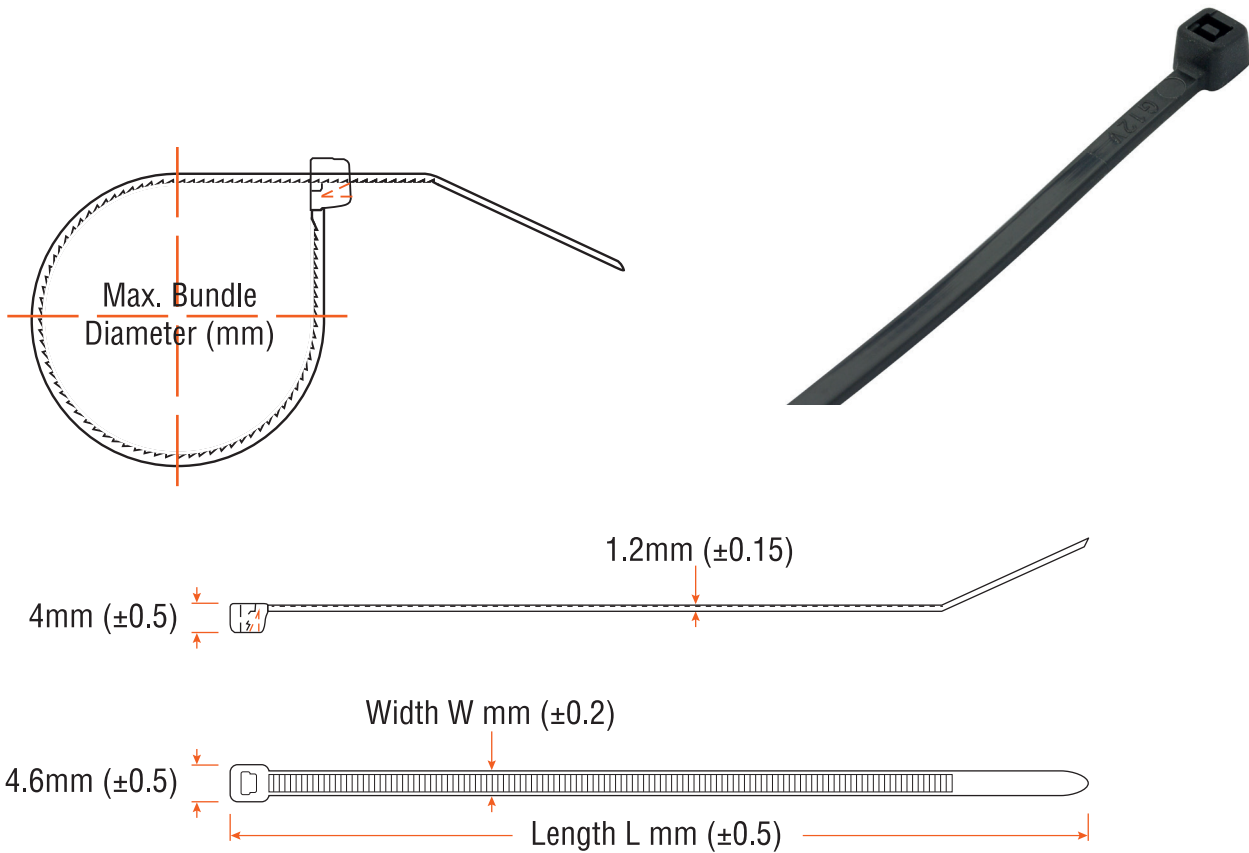

Materials:

UL approved Nylon 66, 94V-2
High tensile strength with low insertion force
Excellent resistance to weathering and ageing

Feature:

Suitable for a multitude of uses in various industries

Application:

Self-locking for fast and easy application.

Operating Temperature:

-40°C to +85°C



Cable Ties (Pack 100) – Miniature Range

| Order code | MPN | Colour | Width W (mm) | Length L (mm) | Max. Bundle Diameter (mm) | Min. Tensile Strength (kg) |
|----------------|------------|---------|--------------|---------------|---------------------------|----------------------------|
| | UNI-CT22-B | Black | 2.5 | 80 | 16 | 8 |
| 04-0861 | UNI-CT1-B | Black | 2.5 | 100 | 22 | 8 |
| | UNI-CT38-B | Black | 2.5 | 120 | 28 | 8 |
| 04-0862 | UNI-CT23-B | Black | 2.5 | 165 | 43 | 8 |
| 04-0863 | UNI-CT4-B | Black | 2.5 | 200 | 55 | 8 |
| | UNI-CT47-B | Black | 2.5 | 250 | 68 | 8 |
| | UNI-CT53-B | Black | 2.5 | 400 | 116 | 8 |
| | UNI-CT22-W | Natural | 2.5 | 80 | 16 | 8 |
| 04-0864 | UNI-CT1-W | Natural | 2.5 | 100 | 22 | 8 |
| | UNI-CT38-W | Natural | 2.5 | 120 | 28 | 8 |
| 04-0865 | UNI-CT23-W | Natural | 2.5 | 165 | 43 | 8 |
| 04-0866 | UNI-CT4-W | Natural | 2.5 | 200 | 55 | 8 |
| | UNI-CT47-W | Natural | 2.5 | 250 | 68 | 8 |
| | UNI-CT53-W | Natural | 2.5 | 400 | 116 | 8 |