


Cable Ties (Pack 100) - Miniature Range

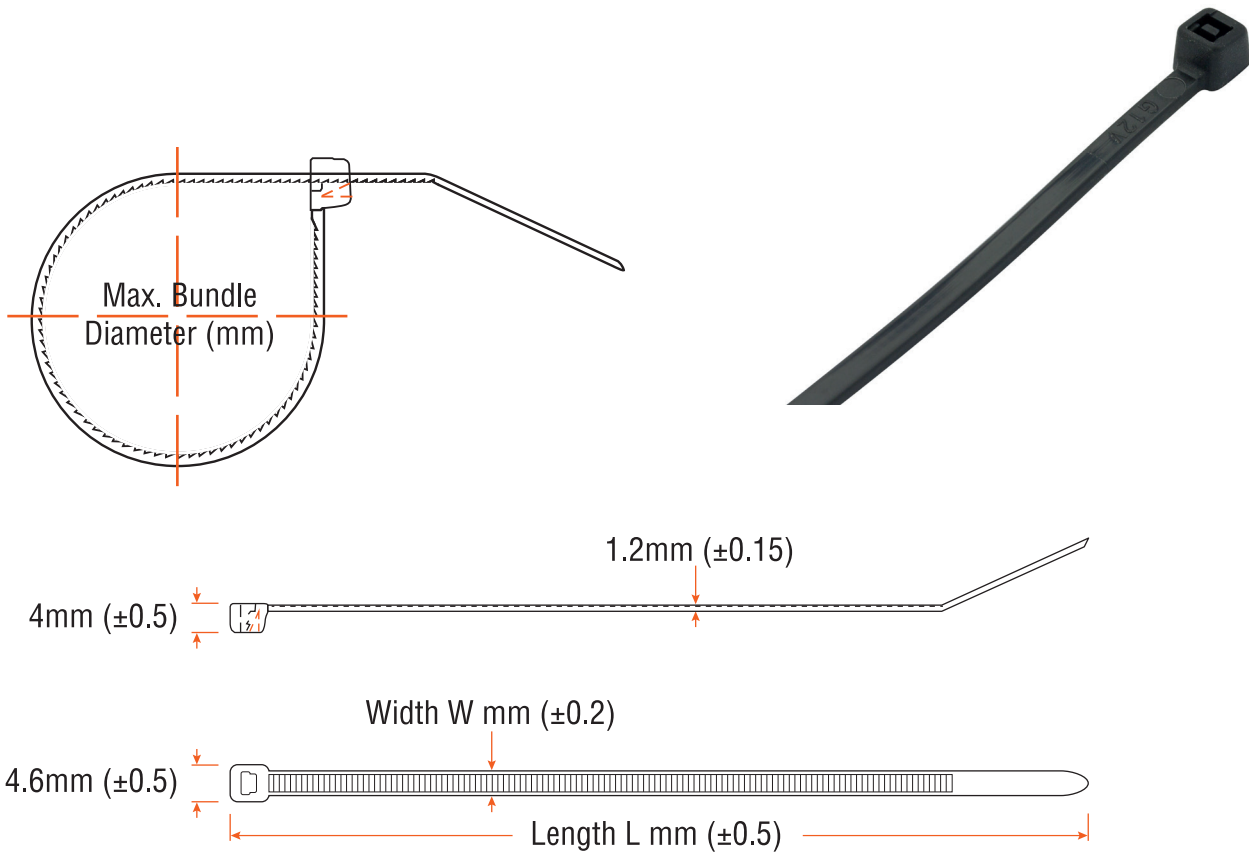

Materials:

UL approved Nylon 66, 94V-2
High tensile strength with low insertion force
Excellent resistance to weathering and ageing

Feature:

Suitable for a multitude of uses in various industries

Application:

Self-locking for fast and easy application.

Operating Temperature:

-40°C to +85°C



Cable Ties (Pack 100) – Miniature Range

Order code	MPN	Colour	Width W (mm)	Length L (mm)	Max. Bundle Diameter (mm)	Min. Tensile Strength (kg)
	UNI-CT22-B	Black	2.5	80	16	8
04-0861	UNI-CT1-B	Black	2.5	100	22	8
	UNI-CT38-B	Black	2.5	120	28	8
04-0862	UNI-CT23-B	Black	2.5	165	43	8
04-0863	UNI-CT4-B	Black	2.5	200	55	8
	UNI-CT47-B	Black	2.5	250	68	8
	UNI-CT53-B	Black	2.5	400	116	8
	UNI-CT22-W	Natural	2.5	80	16	8
04-0864	UNI-CT1-W	Natural	2.5	100	22	8
	UNI-CT38-W	Natural	2.5	120	28	8
04-0865	UNI-CT23-W	Natural	2.5	165	43	8
04-0866	UNI-CT4-W	Natural	2.5	200	55	8
	UNI-CT47-W	Natural	2.5	250	68	8
	UNI-CT53-W	Natural	2.5	400	116	8