


## Cable Ties (Pack 100) - Miniature Range

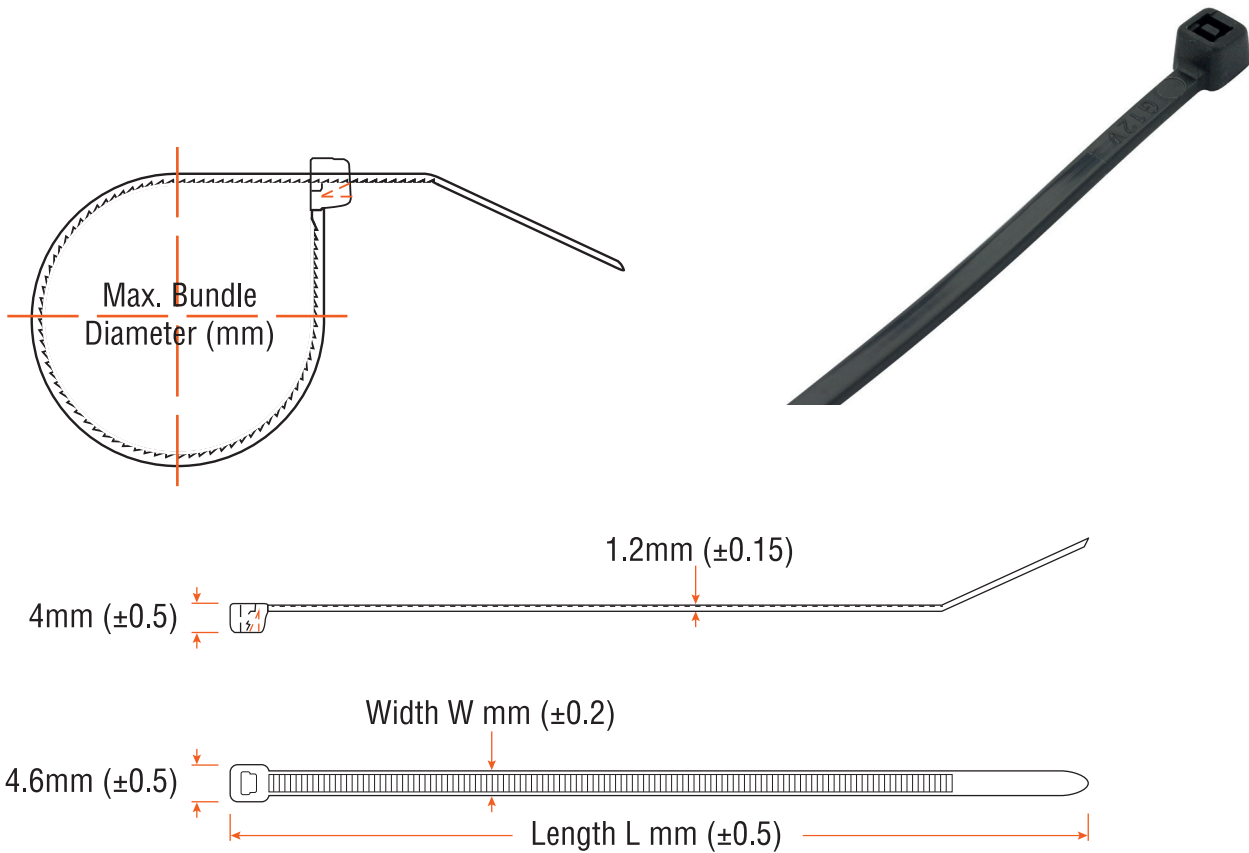

**Materials:**

UL approved Nylon 66, 94V-2  
High tensile strength with low insertion force  
Excellent resistance to weathering and ageing

**Feature:**

Suitable for a multitude of uses in various industries

**Application:**

Self-locking for fast and easy application.

**Operating Temperature:**

-40°C to +85°C



# Cable Ties (Pack 100) – Miniature Range

Order code	MPN	Colour	Width W (mm)	Length L (mm)	Max. Bundle Diameter (mm)	Min. Tensile Strength (kg)
	UNI-CT22-B	Black	2.5	80	16	8
<b>04-0861</b>	UNI-CT1-B	Black	2.5	100	22	8
	UNI-CT38-B	Black	2.5	120	28	8
<b>04-0862</b>	UNI-CT23-B	Black	2.5	165	43	8
<b>04-0863</b>	UNI-CT4-B	Black	2.5	200	55	8
	UNI-CT47-B	Black	2.5	250	68	8
	UNI-CT53-B	Black	2.5	400	116	8
	UNI-CT22-W	Natural	2.5	80	16	8
<b>04-0864</b>	UNI-CT1-W	Natural	2.5	100	22	8
	UNI-CT38-W	Natural	2.5	120	28	8
<b>04-0865</b>	UNI-CT23-W	Natural	2.5	165	43	8
<b>04-0866</b>	UNI-CT4-W	Natural	2.5	200	55	8
	UNI-CT47-W	Natural	2.5	250	68	8
	UNI-CT53-W	Natural	2.5	400	116	8