


- Materials:** UL approved Nylon 66, 94V-2
- Adhesives:** Double coated polyethylene foam tape (acrylic, 0.62mm thickness)
- Feature:** Self-adhesive tie mounts are designed to support light weight wire bundles
- Application:** For heavy support, mounting hole is provided for screws
- Operating Temp:** -40°C to +85°C

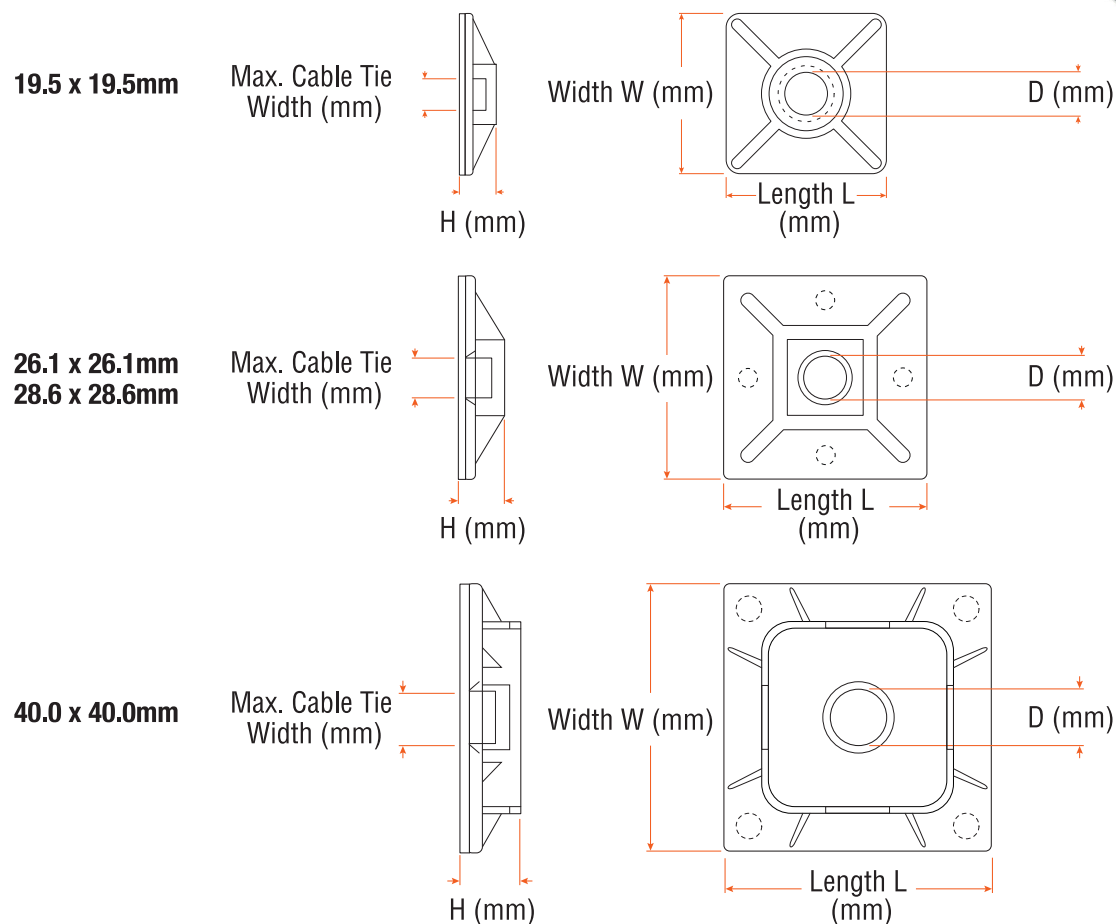

| Order code     | MPN           | Colour  | Width W (mm) | Length L (mm) | Dimensions H (mm) | Suitable for Max. Cable Tie Width (mm) | Hole (mm) |
|----------------|---------------|---------|--------------|---------------|-------------------|----------------------------------------|-----------|
| <b>04-0915</b> | UNI-CA19x19-B | Black   | 19.5         | 19.5          | 3.9               | 4.6                                    | 5.2       |
|                | UNI-CA26x26-B | Black   | 26.1         | 26.1          | 6.0               | 8.0                                    | 4.3       |
| <b>04-0917</b> | UNI-CA28x28-B | Black   | 28.6         | 28.6          | 5.3               | 5.5                                    | 5.0       |
|                | UNI-CA40x40-B | Black   | 38.5         | 38.5          | 7.6               | 10.2                                   | 5.0       |
| <b>04-0916</b> | UNI-CA19x19-N | Natural | 19.5         | 19.5          | 3.9               | 4.6                                    | 5.2       |
|                | UNI-CA26x26-N | Natural | 26.1         | 26.1          | 6.0               | 8.0                                    | 4.3       |
| <b>04-0918</b> | UNI-CA28x28-N | Natural | 28.6         | 28.6          | 5.3               | 5.5                                    | 5.0       |
|                | UNI-CA40x40-N | Natural | 38.5         | 38.5          | 7.6               | 10.2                                   | 5.0       |