
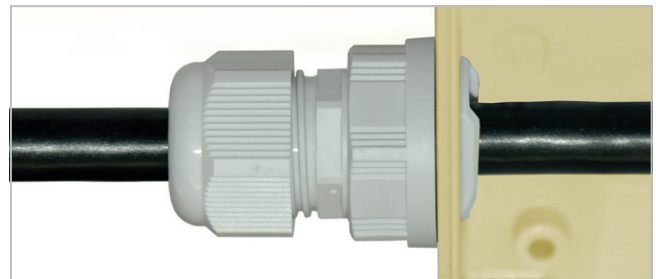


PERFECT Fix cable gland

K341-1xxx-zz

Configuration	
Dome nut	Polyamide PA6 V-2
Sealing ring	Polychloroprene-Nitrile rubber CR/NBR
Gland body	Polyamide PA6 V-2
Mounting nut	Polyamide PA6 GF30
Moulded sealing ring	Nitrile-Polytetrafluorethylene rubber NBR/PTFE
Properties	
<p>quick and easy installation without special tools, trouble-free mounting and dismounting from one side, Locknut on the inner side dispensable, advantageous for installation in areas with limited space, Installation in clearance holes with dimensions according to DIN EN 50262, no inner thread required, continuously adjustable in wall thickness from 1-4 mm, integrated anchorage, wide sealing and clamping range</p>	
Temperature range	-20°C / +100°C
Protection grade	IP68

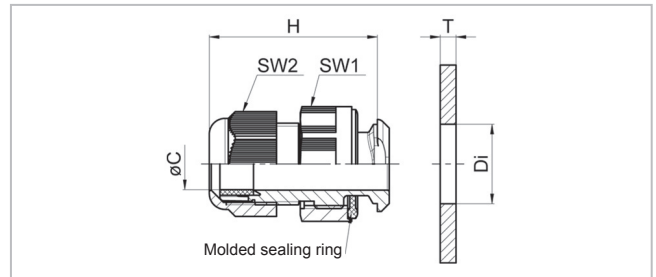

Characteristics

for holes											
Type	Hole Di	Wall thickness T mm	ØC mm	SW1 mm	SW2 mm	H mm	Piece	RAL 7001 silver grey Part No.	RAL 7035 light grey Part No.	RAL 9005 jet black Part No.	
M16	16,1 - 16,4	1 - 4	5 - 10	24	20	38,5	100	K341-1016-01	K341-1016-00	K341-1016-02	
M20	20,1 - 20,4	1 - 4	8 - 13	26	24	42,5	100	K341-1020-01	K341-1020-00	K341-1020-02	
M25	25,1 - 25,4	1 - 4	11 - 17	32	29	48	50	K341-1025-01	K341-1025-00	K341-1025-02	