


## Nylon IP68 Cable Glands

A range of compression type cable glands manufactured in black or grey nylon 66. The glands are designed for use with PVC or rubber circular profile cables and provide protection to **IP68** when tightened with a spanner.

### Features

- Material: UL approved nylon 66 94V-0 (Black)
- “Cable Grab Claw” is designed to stay on the gland body to save installation cost and a rubber ring is provided inside the claw to grip cable firmly
- Good for insulation and protection of cable to go through chassis
- Rated to IP68
- Supplied complete with lock nut
- Metric & PG thread (DIN standard)

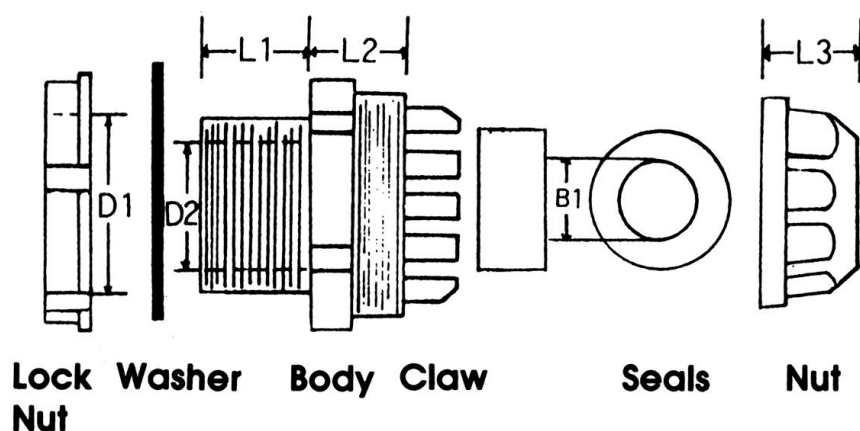

Thread Size	Mounting Hole D1	Pitch (mm)	D2	B1	L1	L2	L3	Cable Range	Colour
PG7	12.1	1.5	8.0	6.0	8.0	12.8	13.4	3.5 - 6	Grey
PG9	14.3		9.9	7.0	8.1	13.9	15.2	4 - 8	Grey
PG11	18.23		13.2	9.6	8.2	15.4	18.3	5 - 10	Grey
PG13.5	19.9		15.2	11.7	8.9	15.8	18.9	6 - 12	Grey
PG16	22.1		17.2	12.9	8.9	17.3	19.7	10 - 14	Grey
PG21	27.5		22.4	16.5	10.8	18.3	23.9	13 - 18	Grey
M12	12	8.3	5.0	7.9	12.1	13.3	3 - 6.5	Black	
M16	16	10.9	9.6	14.4	14.4	16.7	5 - 10	Black	
M20	20	14.8	12.9	12.8	19.5	18.4	10 - 14	Black	
M25	25	18.5	16.5	13.9	19.5	22.3	13 - 18	Black	
M32	32	25.9	23.3	14.6	20.3	26.1	18 - 25	Black	