

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200060240

Status:

Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single-Ended Cordset, 3 Poles, Male (Straight) to Pigtail, 0.34mm² PVC Cable, 2.0m (6.56') Length

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

UL

E152210

General

Product Family

Industrial Cordsets

Series

120006

Connector End A

Micro-Change (M12)

Connector End B

Pigtail

IP Rating

IP67

Material - Contact

Copper Alloy

Overview

Brad Micro-Change (M12) Connectors

Product Name

Micro-Change (M12)

Protocol

N/A

Region

Europe

Type

Single Ended

UPC

883906067045

Physical

Cable Diameter

4.90mm (.193")

Cable Length

2.0m (6.56')

Color - Cable Jacket

Black

Coupling Style

Threaded

Gender

Male-Pigtail

Keyway

Single

LED Indicator

No

Material - Cable Jacket

PVC

Material - Connector Body

PUR

Material - Coupling Nut

Nickel-plated Brass

Material - O-Ring

Fluoro-elastomer

Material - Plating Mating

Gold

Net Weight

79.330/g

Orientation

Straight to Pigtail

Poles

4

Temperature Range - Operating

-30°C TO +80°C

Wire Size AWG

N/A

Wire/Cable Type

UL 2464

Electrical

Current - Maximum per Contact

4.0A

Voltage - Maximum

250V AC/DC

Material Info


Engineering Number

803006E03M020

Reference - Drawing Numbers

Sales Drawing

1200659185-000

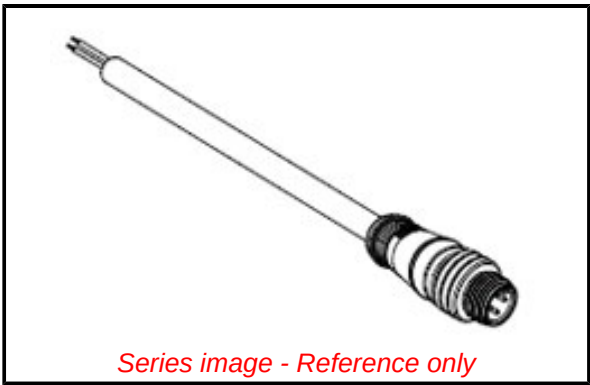

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit

Contact US

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

120006 Series

This document was generated on 08/16/2021

**PLEASE CHECK [WWW.MOLEX.COM](http://WWW.MOLEX.COM) FOR LATEST PART INFORMATION**