

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200710045

Status:


Active

Overview:

Brad Micro-Change (M12) Connectors

Description:

Micro-Change (M12) Single Keyway with PG7 Cable Fitting, Straight Male, 5 Poles, Cable Diameter 3.30-6.60mm

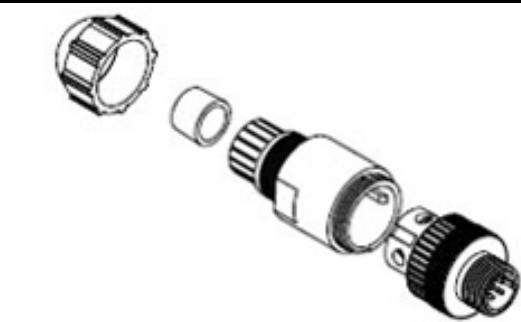

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Field Attachable / Accessories
Series	120071
Approvals	cCSAus certified
IP Rating	IP67
Material - Contact	Brass
Overview	Brad Micro-Change (M12) Connectors
Product Name	Micro-Change (M12)
Type	Field Attachable Connector
UPC	78678875705
Physical	
Cable Diameter	3.30-6.60mm (.130-.260")
Coupling Type	External Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	Single
Material - Connector Body	PA
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Silver
Net Weight	25.401/g
Orientation	Straight
Poles	5
Temperature Range - Operating	-25°C to +90°C
Wire Size AWG	18
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	30V AC / 36V DC
Material Info	
Engineering Number	8A5006-31
Reference - Drawing Numbers	
Sales Drawing	SD-120071-004-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

120071 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION