

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200845113

Status:


Active

Overview:

Brad Ultra-Lock Connection System

Description:

Ultra-Lock (M12) Receptacle, 5 Poles, M16x1.5 Mounting Threads, Female (Straight) to 0.34mm² PVC Leads, 0.30m (11.81") Length

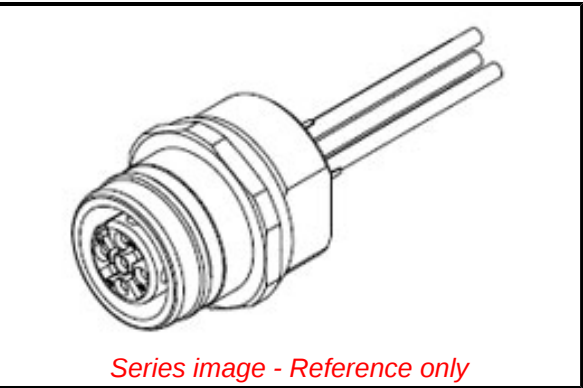

Series image - Reference only

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Industrial Receptacles
Series	120084
IP Rating	IP69K
NEMA Rating	NEMA 6
Overview	Brad Ultra-Lock Connection System
Product Name	Ultra-Lock (M12)
Type	Single Ended (pigtail)
UPC	883906778965
Physical	
Coupling Type	Internal Thread
Gender	Female
Keyway	Single
Length	0.30m
Material - Component	Nickel-plated Brass
Mounting Thread Size	M16 x 1.5
Net Weight	23.161/g
Orientation	Straight
Panel Mount	Front
Poles	5
Temperature Range - Operating	-25°C to +90°C
Wire Size AWG	22
Wire/Cable Type	Leads, UL 1061
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	250V AC/DC
Material Info	
Engineering Number	WR5U20E03C3003
Reference - Drawing Numbers	
Sales Drawing	1200845107-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Contained Per -	
D(2020)9139-DC (19	
Jan 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

120084 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION