

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1200845159](#)
Status: **Active**
Overview: [Brad Ultra-Lock Connection System](#)
Description: Ultra-Lock (M12) Receptacle, 5 Poles, PG9 Mounting Threads, Female (Straight) to 0.34mm² PVC Leads, 0.30m (11.81") Length

Documents:
[Drawing \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification
CSA

LR6837

General

Product Family Industrial Receptacles
Series [120084](#)
IP Rating IP69K
NEMA Rating NEMA 6
Overview [Brad Ultra-Lock Connection System](#)
Product Name Ultra-Lock (M12)
Type Single Ended (pigtail)
UPC 884982225268

Physical

Coupling Type Internal Thread
Gender Female
Keyway Reverse
Length 0.30m
Material - Component Nickel-plated Brass
Mounting Thread Size PG9
Net Weight 3.000/g
Orientation Straight
Panel Mount Front
Poles 5
Temperature Range - Operating -25°C to +90°C
Wire Size AWG 22
Wire/Cable Type Leads, UL 1061

Electrical


Current - Maximum per Contact 4.0A
Voltage - Maximum 250V AC/DC

Material Info

Engineering Number WR5J20E03C3003

Reference - Drawing Numbers

Sales Drawing SD-120084-030-001

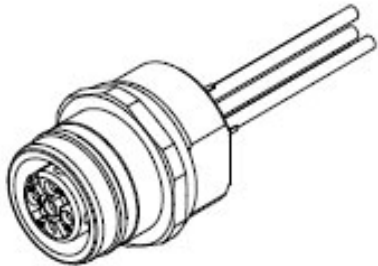

Series image - Reference only

EU ELV

Not Reviewed

EU RoHS

**Compliant with
Exemption 6(c)**

REACH SVHC

Contained Per -
D(2020)9139-DC (19
Jan 2021)
Lead

Halogen-Free

Status

Not Relevant

For more information, please visit [Contact US](#)

China ROHS	Not Relevant
ELV	Not Reviewed
RoHS Phthalates	Not Contained

Search Parts in this Series
[120084](#) Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION