

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1200910010

Status:


Active

Overview:

Brad Nano-Change (M8) Products

Description:

Nano-Change (M8) Attachable Connectors, Straight Male, 4 Poles

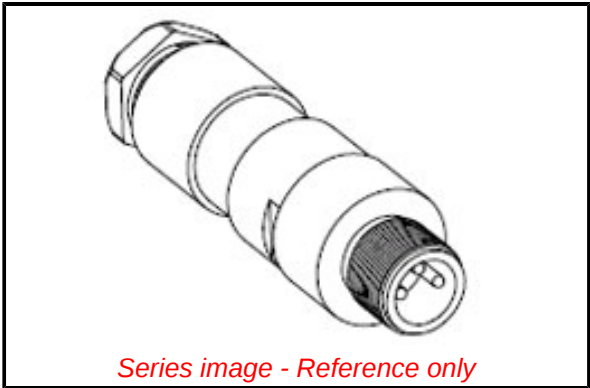

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)
General	
Product Family	Field Attachable / Accessories
Series	120091
IP Rating	IP67
Material - Contact	Brass
Overview	Brad Nano-Change (M8) Products
Product Name	Nano-Change (M8)
Type	Field Attachable Connector
UPC	78678832515
Physical	
Cable Diameter	3.50-5.00mm (.138-.197")
Coupling Type	External Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Male
Keyway	None
Material - Connector Body	Polyamide
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	8.072/g
Orientation	Straight
Poles	4
Temperature Range - Operating	0°C to +80°C
Wire Size AWG	N/A
Electrical	
Current - Maximum per Contact	4.0A
Voltage - Maximum	60V AC / 75V DC
Material Info	
Engineering Number	N04MA03124
Reference - Drawing Numbers	
Sales Drawing	SD-120091-001-001

EU ELV

Not Relevant

EU RoHS

Compliant with Exemption 6(c)

REACH SVHC

Not Contained Per -ED/01/2018 (15 January 2018)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China RoHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

120091 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION