

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300170004

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change Field Attachable, Female Connector, 3 Pole, Cable Range: 5.08-11.43mm Outside Diameter with Internal Threads

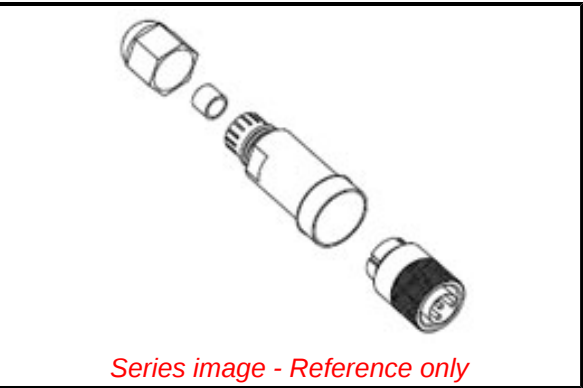

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Field Attachable / Accessories
Series	130017
Approvals	cCSAus certified
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Field Attachable Connector
UPC	78172553098
Physical	
Cable Diameter	5.08-11.43mm (.200-.450")
Coupling Type	Internal Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	Single
Material - Connector Body	Nylon
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	47.000/g
Orientation	Straight
Poles	3
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	15 to 24
Electrical	
Current - Maximum per Contact	13.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	1A3000-34
Reference - Drawing Numbers	
Sales Drawing	SD-130017-002-001

EU ELV

Not Relevant

EU RoHS

China RoHS

Compliant with Exemption 6(c)

REACH SVHC

Contained Per - D(2020)9139-DC (19 Jan 2021)

Lead

Halogen-Free

Status

Not Low-Halogen

For more information, please visit Contact US

China ROHS

50 Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

130017 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION