

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1300170023

Status:


Active

Overview:

Brad Mini-Change Connectors

Description:

Mini-Change Field Attachable, Female Connector, 5 Pole, Cable Range: 5.08-11.43mm Outside Diameter with Internal Threads

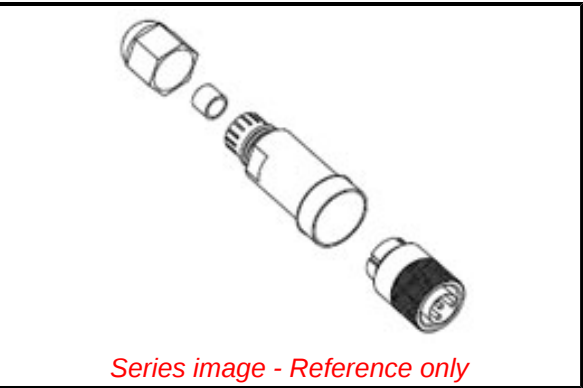

Documents:	
Drawing (PDF)	RoHS Certificate of Compliance (PDF)

Agency Certification	
CSA	LR6837
General	
Product Family	Field Attachable / Accessories
Series	130017
Approvals	cCSAus certified
IP Rating	IP67
Material - Contact	Copper Alloy
Overview	Brad Mini-Change Connectors
Product Name	Mini-Change
Type	Field Attachable Connector
UPC	78172553092
Physical	
Cable Diameter	5.08-11.43mm (.200-.450")
Coupling Type	Internal Thread
Diagnostics / LEDs	No
Diagnostics Port	No
Gender	Female
Keyway	Single
Material - Connector Body	Nylon
Material - Coupling Nut	Nickel-plated Brass
Material - Plating Mating	Gold
Net Weight	50.000/g
Orientation	Straight
Poles	5
Temperature Range - Operating	-20°C to +80°C
Wire Size AWG	15 to 24
Electrical	
Current - Maximum per Contact	8.0A
Voltage - Maximum	600V AC/DC
Material Info	
Engineering Number	1A5000-34
Reference - Drawing Numbers	
Sales Drawing	SD-130017-001-001

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2020)9139-DC (19 Jan 2021)	
Lead	
Halogen-Free	
Status	
Not Low-Halogen	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

130017 Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION