

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1727040009

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT Standard-Density D-Sub Crimp Housing, Male, Shell with Dimples, 9 Circuits

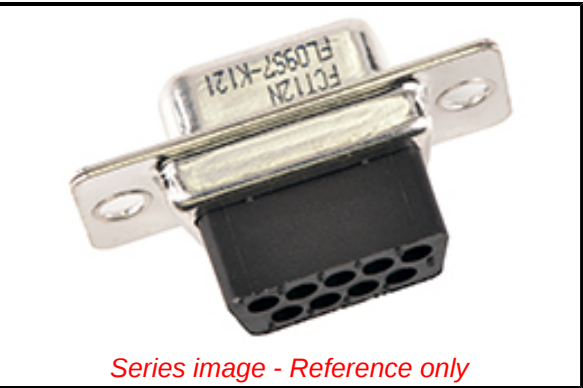

Documents:	
Datasheet (PDF)	RoHS Certificate of Compliance (PDF)
Brochure (PDF)	

General	
Product Family	D-Sub Products
Series	172704
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	Standard Density
UPC	889056019101
Physical	
Circuits (Loaded)	0
Circuits (maximum)	9
Color - Resin	Black
Gender	Male
Material - Resin	PBT, Polyamide
Material - Shell	Steel
Net Weight	4.600/g
Number of Rows	2
Orientation	Straight
PCB Locator	No
PCB Retention	None
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.84mm
Plating - Shell	Tin
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +115°C
Termination Style	Crimp
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Wire Size AWG	18, 20, 22, 24, 26, 28
Material Info	
Engineering Number	FL09P7-K120

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Contained Per - D(2020)4578-DC (25 June 2020)	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	Green Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
172704 Series
Mates With
FCT Standard-Density D-Sub, Size 1, 9 Position, Socket
Use With
FCT Standard-Density Male Crimp Contacts 1731120200 , 1731120201 , 1731120202

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION