


PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [1727040130](#)
Status: **Active**
Overview: [FCT D-Sub Connectors](#)
Description: FCT Coaxial Contact, Male, Straight, Solder Cable Termination, 50 Ohms, 1.30µm Gold Plating, without Inspection Hole, for RG-174U, RG-188AU, or RG-316U Cable

Documents:
[Brochure \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General	
Product Family	D-Sub Products
Series	172704
Contact Type	Coaxial
Overview	FCT D-Sub Connectors
Product Category	Contacts
Product Name	FCT Products
Type	Mixed Layout
UPC	889056020411
Wire/Cable Type	RG-174U, RG-188AU, RG-316U
Physical	
Durability (mating cycles max)	200
Gender	Male
Material - Contact	Copper Alloy
Net Weight	1.400/g
Orientation	Straight
Packaging Type	Bag
Plating - Contact	Gold over Nickel
Plating min - Mating	0.800µm
Plating min - Termination	1.300µm
Temperature Range - Operating	-55° to +135°C
Termination Style	Solder
Electrical	
Current - Maximum per Contact	2.0A
Impedance	50Ω
Material Info	
Engineering Number	FMX006P102

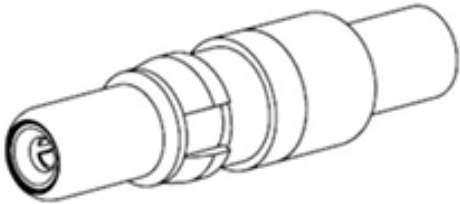

Series image - Reference only

EU ELV Not Relevant	
EU RoHS Compliant with Exemption 6(c) REACH SVHC Not Relevant Halogen-Free Status Not Relevant For more information, please visit Contact US	China RoHS
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series
[172704](#) Series

Use With
FCT Mixed Layout Connectors

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION