

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1731070068

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT Mixed Layout D-Sub Connector, Female, Straight, Solder Cup, Gold Plating, Tin-plated Shell without Dimples, 21 Circuits, 17 Signal Contacts Loaded

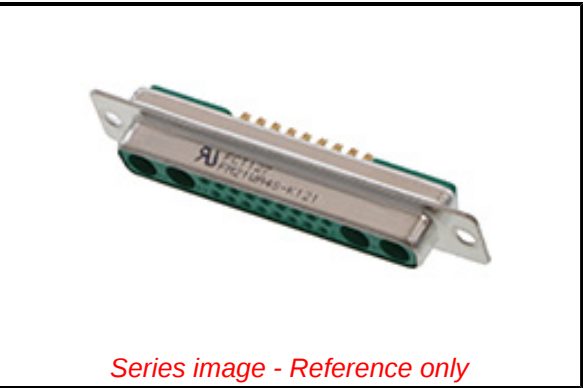

Series image - Reference only

Documents:

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

Brochure (PDF)

General	
Product Family	D-Sub Products
Series	173107
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Taxonomy	D-Sub Connectors
Type	Mixed Layout
UPC	889056318921
Physical	
Circuits (Loaded)	17
Circuits (maximum)	21
Color - Resin	Green
Durability (mating cycles max)	500
Gender	Female
Material - Contact	Copper Alloy
Material - Resin	PBT
Material - Shell	Steel
Net Weight	13.800/g
Number of Rows	2
Orientation	Straight
PCB Locator	No
PCB Retention	None
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
Pitch - Mating Interface	2.84mm
Pitch - Termination Interface	2.84mm
Plating - Contact	Gold over Nickel
Plating - Shell	Tin
Plating min - Mating	0.800µm
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +130°C
Termination Style	Solder Cup
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Wire Size AWG	20
Electrical	
Current - Maximum per Contact	7.5A
Material Info	
Engineering Number	FM21WA4S-K121

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant with Exemption 6(c)	
REACH SVHC	
Contained Per - D(2022)4187-DC (10 June 2022)	
Lead	
Halogen-Free	
Status	
Not Reviewed	
For more information, please visit Contact US	
China ROHS	50 Image
ELV	Not Relevant
RoHS Phthalates	Not Contained

Search Parts in this Series

173107 Series

Mates With

FCT Mixed Layout D-Sub, Size 4, 21WA4, Plug

Use With

FCT Coaxial, High Power, High Voltage, or Pneumatic Contacts

This document was generated on 01/23/2023

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION