

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1731090035

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT High-Density D-Sub Crimp Housing, Male, 15 Circuits

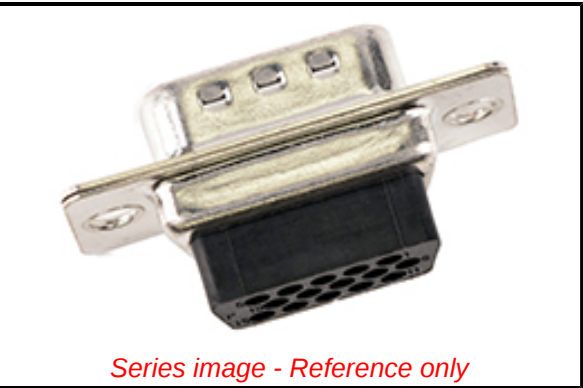

Documents:	
Datasheet (PDF)	RoHS Certificate of Compliance (PDF)
Brochure (PDF)	
General	
Product Family	D-Sub Products
Series	173109
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	High Density
UPC	889056291194
Physical	
Circuits (Loaded)	0
Circuits (maximum)	15
Color - Resin	Black
Durability (mating cycles max)	500
Gender	Male
Material - Resin	PBT
Material - Shell	Steel
Net Weight	4.300/g
Number of Rows	3
Orientation	Straight
PCB Locator	No
PCB Retention	None
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
Pitch - Mating Interface	1.98mm
Pitch - Termination Interface	1.98mm
Plating - Shell	Tin
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +105°C
Termination Style	Crimp
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Wire Size AWG	22, 24, 26, 28
Material Info	
Engineering Number	FL09-15P7
Reference - Drawing Numbers	
Sales Drawing	1731090035-000

EU ELV

Not Relevant

EU RoHS

Compliant

China RoHS

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Not Relevant

For more information, please visit

Contact US

China ROHS

Not Relevant

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

173109 Series

Mates With

FCT High-Density D-Sub, Size 1, 15
Position, Socket

Use With

FCT High-Density Male Crimp Contacts
1731120223 , 1731120224 , 1731120225

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION