

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1731090036

Status:


Active

Overview:

FCT D-Sub Connectors

Description:

FCT High-Density D-Sub Crimp Housing, Female, 15 Circuits

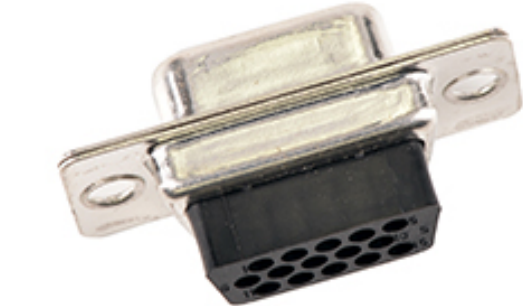

Series image - Reference only

Documents:

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

Brochure (PDF)

General	
Product Family	D-Sub Products
Series	173109
IP Rating	IP20
Overview	FCT D-Sub Connectors
Product Category	D-Sub Connector
Product Name	FCT Products
Type	High Density
UPC	889056291200
Physical	
Circuits (Loaded)	0
Circuits (maximum)	15
Color - Resin	Black
Durability (mating cycles max)	500
Gender	Female
Material - Resin	PBT
Material - Shell	Steel
Net Weight	4.100/g
Number of Rows	3
Orientation	Straight
PCB Locator	No
PCB Retention	None
Packaging Type	Carton
Panel Mount	Rear
Panel Mount Method	Flange
Pitch - Mating Interface	1.98mm
Pitch - Termination Interface	1.98mm
Plating - Shell	Tin
Polarized to Mating Part	Yes
Ports	1
Shielded	Yes
Temperature Range - Operating	-55° to +105°C
Termination Style	Crimp
Waterproof / Dustproof	No
Waterproof / Dustproof Type	IP20
Wire Size AWG	22, 24, 26, 28
Material Info	
Engineering Number	FL09-15S7
Reference - Drawing Numbers	
Sales Drawing	1731090036-000

EU ELV	
Not Relevant	
EU RoHS	China RoHS
Compliant	
REACH SVHC	
Not Relevant	
Halogen-Free	
Status	
Not Relevant	
For more information, please visit Contact US	
China ROHS	Not Relevant
ELV	Not Relevant
RoHS Phthalates	Not Relevant

Search Parts in this Series

173109 Series

Mates With

FCT High-Density D-Sub, Size 1, 15 Position, Plug

Use With

FCT High-Density Female Crimp Contacts 1731120226 , 1731120227 , 1731120228

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION