

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

1731120644

Status:

Active

Overview:

FCT D-Sub Connectors

Description:


FCT Stamped Contact, Female, Crimp, 0.80µm Gold Plating, Split Tine, 20-24 AWG

Documents:

Brochure (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	D-Sub Products
Series	173112
Comments	Packaging Detail: 10 strips of 25 pieces in a box
Contact Type	Stamped Crimp
Overview	FCT D-Sub Connectors
Product Category	Contacts
Product Name	FCT Products
Taxonomy	D-Sub Contacts
Type	Standard Density
UPC	191128466400
Physical	
Durability (mating cycles max)	500
Gender	Female
Material - Contact	Copper Alloy
Net Weight	0.200/g
Orientation	Straight
Packaging Type	Carton
Plating - Contact	Gold over Nickel
Plating min - Mating	0.800µm
Temperature Range - Operating	-55° to +125°C
Termination Style	Crimp
Wire Size AWG	20, 22, 24
Electrical	
Current - Maximum per Contact	5.0A
Material Info	
Engineering Number	S7L-K176

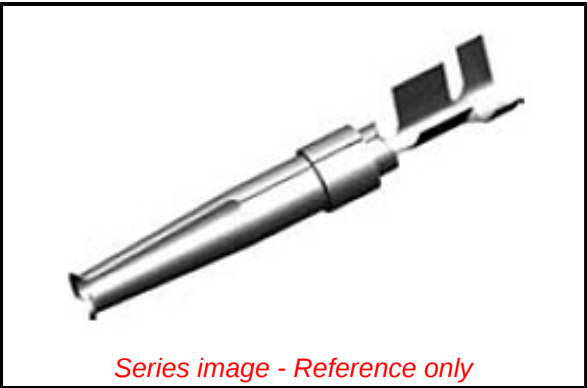

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2021)10043-DC (17
Jan 2022)

Halogen-Free

Status

Not Reviewed

For more information, please visit

Contact US

China ROHS

Green Image

ELV

Not Relevant

RoHS Phthalates

Not Contained

Search Parts in this Series

173112 Series

Use With

FCT Standard-Density Connectors

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION