

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0190030068

Status:

Active

Overview:

Standard Quick-Disconnect Terminals

Description:

InsulKrimp Quick Disconnect, Female, for 24-26 (0.20-0.12mm²), Bag, Tab 4.75 x 0.81mm, Dark Yellow

Documents:

- [3D Model](#)
- [3D Model \(PDF\)](#)
- [Drawing \(PDF\)](#)
- [Product Specification PS-19902-008-001 \(PDF\)](#)
- [Product Specification PS-19902-011-001 \(PDF\)](#)
- [Product Specification PS-19902-013-001 \(PDF\)](#)
- [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family

Series

Comments

Crimp Quality Equipment

Insulated

Overview

Product Name

Type

UPC

Quick Disconnects

19003

Funnel Entry

Yes

Fully

Standard Quick-Disconnect Terminals

InsulKrimp

Quick Disconnect

800754884006

Physical

Barrel Type

Color - Resin

Gender

Glow-Wire Capable

Insulation

Lock to Mating Part

Material - Metal

Material - Plating Mating

Material - Plating Termination

Material - Resin

Net Weight

Orientation

Packaging Type

Plating min - Mating

Plating min - Termination

Polarized to Mating Part

Tab Thickness

Tab Width

Temperature Range - Operating

Termination Interface: Style

Wire Insulation Diameter

Wire Size AWG

Closed

Yellow (Dark)

Female

No

Nylon (PA)

None

Brass

Tin

Tin

Nylon

0.726/g

Straight

Bag

4.064µm

4.064µm

No

0.81mm

4.75mm

-65° to +105°C

Crimp or Compression

1.90mm max.

24, 26

Electrical

Voltage - Maximum

600V

Solder Process Data

Lead-freeProcess Capability


N/A

Material Info

Engineering Number

M-2211

Reference - Drawing Numbers

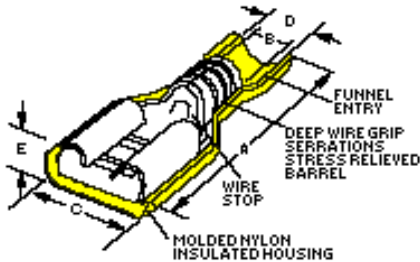

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained Per -
D(2020)9139-DC (19
Jan 2021)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

19003 Series

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
PremiumGrade	640015200
Hand Crimp Tool for Insulkrimp Female Fully Insulated Quick Disconnect, 24-26 AWG	
Crimp Head for the AT-200 Pneumatic Hand Tool	640055200

Product Specification

Sales Drawing

PS-19902-008-001, PS-19902-011-001,
PS-19902-013-001
SD-19003-005-001

This document was generated on 08/18/2021

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION